



# Classic filament LEDbulbs

## 12A19/LED/927/FR/Glass/E26/DIM 1FB T20

Philips LED vintage-style lamps allow you to maintain a warm, classic light effect while providing longer life and energy savings.

### Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal lifetime	15,000 hour(s)
Switching Cycle	20,000
Lighting Technology	LED
EU RoHS compliant	Yes

Light Technical	
Color Code	927 [CCT of 2700K]
Beam Angle (Nom)	320 degree(s)
Luminous Flux	1,600 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	133.00 lm/W
Color Consistency	<4
Color rendering index (CRI)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and Electrical	
Line Frequency	60 Hz
Input Frequency	60 Hz
Power Consumption	12 W

Lamp Current (Nom)	105 mA
Wattage Equivalent	100 W
Starting Time (Nom)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.7
Voltage (Nom)	120 V

Temperature	
Ambient temperature range	-4 °F to 113 °F

Controls and Dimming	
Dimmable	Only with specific dimmers

Mechanical and Housing	
Bulb Finish	Frosted
Bulb Material	Glass
Bulb Shape	A19 [A 19mm]
UL Wet/ damp/ dry location	Wet location


Approval and Application	
Energy Certifications	Energy Star

# Classic filament LEDbulbs

T20 compliant	Yes
<b>Application Conditions</b>	
can it be used in closed luminaires	Yes
<b>Product Data</b>	
Order product name	12A19/LED/927/FR/Glass/E26/DIM 1FB T20
Full product name	12A19/LED/927/FR/Glass/E26/DIM 1FB T20



Order code	578617
Material Nr. (12NC)	929003498204
Numerator - Quantity Per Pack	1
EAN/UPC - Product/Case	046677578619
Numerator - Packs per outer box	10
EAN/UPC - Case	50046677578614

## Dimensional drawing

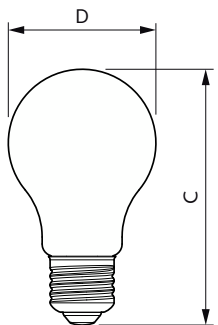


Product	D	C
12A19/LED/927/FR/Glass/E26/DIM 1FB T20	2-5/8 inch	4-9/16 inch

## Photometric data

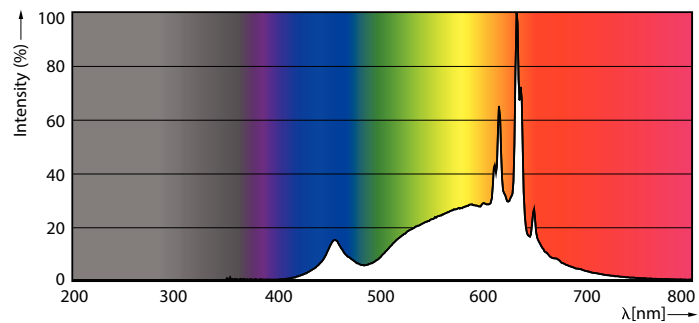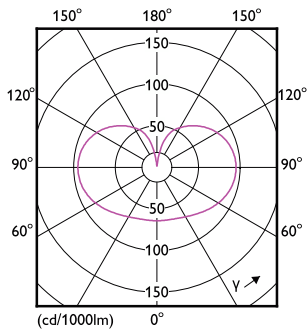

Light Distribution Diagram - 12A19/LED/927/FR/Glass/E26/DIM 1FB T20

Spectral Power Distribution Colour - 12A19/LED/927/FR/Glass/E26/DIM 1FB T20

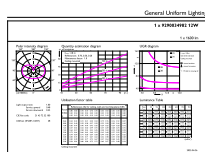

General uniform lighting - 12A19/LED/927/FR/Glass/E26/DIM 1FB T20

# Classic filament LEDbulbs

## Lifetime



Life Expectancy Diagram - 12A19/LED/927/FR/Glass/E26/DIM 1FB T20

Lumen Maintenance Diagram - 12A19/LED/927/FR/Glass/E26/DIM 1FB T20

