


Keysight Technologies
Rackmount Accessory Products
Cross Reference Guide


Selection Guide

Introduction


Rackmount accessory products provide rackmount accessory solutions for your Keysight Technologies, Inc. instrument assets. These accessory products are being released in two waves, starting in May, 2011. These products are offered for standalone sales, and qualify for standard discounts. The *Keysight Rackmount Accessory Cross Reference Selection Guide* is designed to assist you in selecting the correct product to meet your needs. Simply identify the instrument needing the rackmount accessory, then look in the column corresponding to the type of accessory needed to find the accessory product number to order. Additional information is provided to help identify the correct item including the original instrument option for the accessory, the part number of the key component making up the accessory, and the accessory description. Keysight will be adding additional rackmount accessory products to broaden coverage to more instruments and more mounting options in the near future.

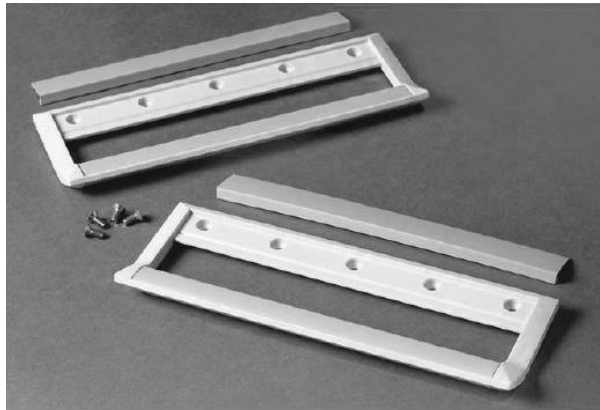


Handle products

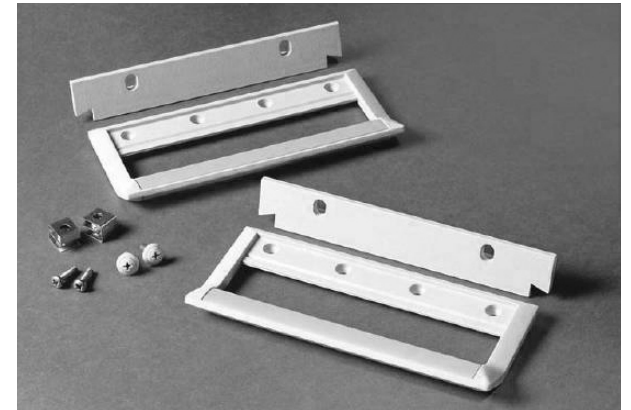

Rackmount flanges with handles

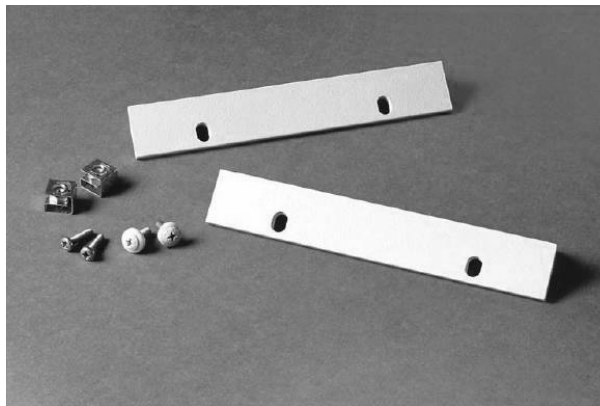

Rackmount flange products

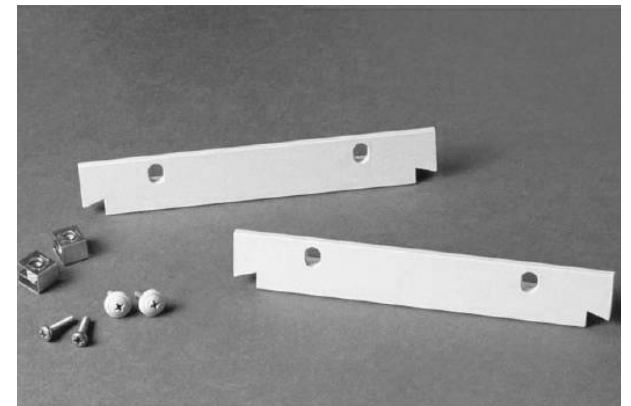

Rackmount flanges for instruments with existing handles

Introduction 2

1CP Series Rackmount Accessories Including Handles..... 3

1CM Series Rackmount Accessories for Instruments
without Handles 4

1CM Series Rackmount Accessories for Instruments
with Previously Supplied Handles 4

1CM Series Rackmount Adapter Kits 5

1CN Series Handles 5


Technical Specifications..... 6

Contact Keysight..... 96

1CP Series Rackmount Accessories Including Handles

Maneuver and securely mount your Keysight products into rack enclosures

Rackmount flange kits are available for all System II instruments. Flanges attach to pre-existing holes in the instrument case. These flanges have a notch for handles, and this kit includes both flanges and handles.

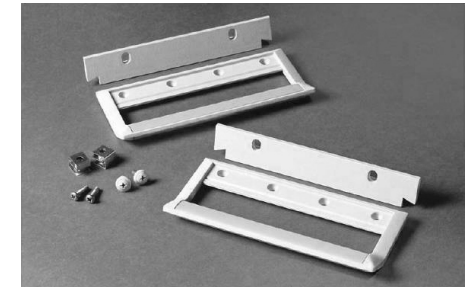


Instrument module height	Rackmount flange kit with handles (order new product if available)	New rackmount product (currently available if populated)
88.1 mm (3.5 in)	5063-9219	1CP011A
88.1 mm (3.5 in)	5063-9220	Future release, order 5063-9220
132.6 mm (5.25 in)	5063-9221	1CP008A
177.0 mm (7.0 in)	5063-9222	1CP005A
221.5 mm (8.75 in)	5063-9223	1CP020A
265.9 mm (10.5 in)	5063-9224	1CP019A
310.4 mm (12.25 in)	5063-9225	Future release, order 5063-9225
Kit includes	2 flanges, 2 handles, mounting screws, metric fasteners	
The following kits use standard flanges with 1.75 in hole spacing: 5063-9212/9219/9232		
The following kits use special flange with 3 in hole spacing: 5063-9213/9220		

1CM Series Rackmount Accessories for Instruments without Handles

Securely mount your Keysight products into rack enclosures

Rackmount flange kits are available for all System II instruments. Flanges attach to pre-existing holes in the instrument case. These flanges do not have a notch for handles, and therefore cannot be used for instruments that have handles.

- Will not fit onto instruments with previously supplied handles.

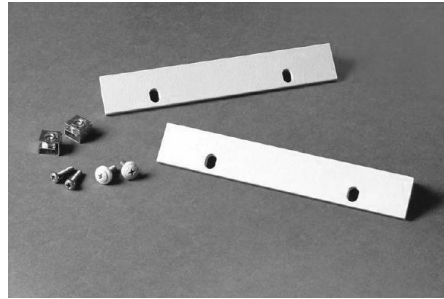


Instrument module height	Rackmount flange kit (order new product if available)	New rackmount product (currently available, if populated)
88.1 mm (3.5 in)	5063-9212	34191A
132.6 mm (5.25 in)	5063-9214	34192A
177.0 mm (7.0 in)	5063-9215	1CM013A
221.5 mm (8.75 in)	5063-9216	1CM015A
265.9 mm (10.5 in)	5063-9217	1CM042A
310.4 mm (12.25 in)	5063-9218	1CM033A
Kit includes	2 flanges, mounting screws, metric fasteners	
The following kits use standard flanges with 1.75 in hole spacing: 5063-9212/9219/9232		
The following kits use special flanges with 3 in hole spacing: 5063-9213/9220		

1CM Series Rackmount Accessories for Instruments with Previously Supplied Handles

Securely mount your Keysight products into rack enclosures

Certain Keysight instruments are supplied with front handles. These flange kits have a special cut out to accommodate the handles.


- Flanges attach to pre-existing holes in the instrument case.

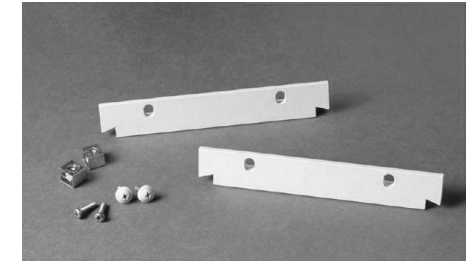


Instrument module height	Rackmount flange kit for instruments with previously supplied handles (order new product if available)	New rackmount product (currently available, if populated)
88.1 mm (3.5 in)	5063-9232	Future release, order 5063-9232
132.6 mm (5.25 in)	5063-9234	Future release, order 5063-9234
221.5 mm (8.75 in)	5063-9236	1CM043A
265.9 mm (10.5 in)	5063-9237	Future release, order 5063-9237
Kit includes	2 flanges, mounting screws, metric fasteners	
The following kits use standard flanges with 1.75 in hole spacing: 5063-9212/9219/9232		
The following kits use special flanges with 3 in hole spacing: 5063-9213/9220		

1CM Series Rackmount Adapter Kits

Securely mount your Keysight products with pre-existing handles into rack enclosures

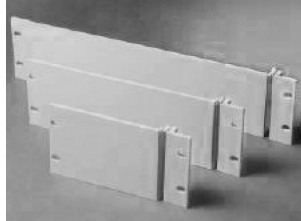

Rackmount adapter kits for 88.1 mm instrument module height (5063-9239, 5063-9240 (34190A), 5063-9241, 1CM019A)

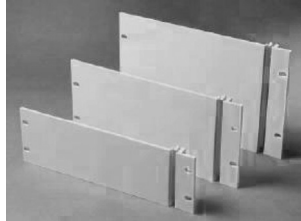

Rackmount adapter kits for half-modules (5063-9240 (34190A), 5063-9243 (34193A), 5063-9245)



Rackmount adapter kit with mounting hardware (5063-9239)

Instrument module height	Rackmount adapter kit mounts ¼-width modules	New product (currently available, if populated)
88.1 mm (3.5 in)	5063-9239	Future release, order 5063-9239

132.6 mm (5.25 in)	–	–
177.0 mm (7.0 in)	–	–
Kit includes	1 rack flange + 1 three-quarter-module flange, screws	
Side-by-side modules of equal depth require a lock link kit (5061-9694) ¼-module flange can be center mounted using two of these kits		

Instrument module height	Rackmount adapter kit mounts ½-width modules or 2 ¼-width modules	New product (currently available, if populated)
88.1 mm (3.5 in)	5063-9240	34190A
132.6 mm (5.25 in)	5063-9243	34193A
177.0 mm (7.0 in)	5063-9245	1CM068A

Kit includes	1 rack flange + 1 half-module flange, screws	
Side-by-side modules of equal depth require a lock link kit (5061-9694) ¼-module flange can be center mounted using two of these kits		

Instrument module height	Rackmount adapter kit ¾-width modules (3 each or ¼- and ½-width modules side by side)	New product (currently available, if populated)
88.1 mm (3.5 in)	5063-9241	1CM019A


132.6 mm (5.25 in)	–	–
177.0 mm (7.0 in)	–	–
Kit includes	1 rack flange + 1 quarter-module flange, screws	
Side-by-side modules of equal depth require a lock link kit (5061-9694) ¼-module flange can be center mounted using two of these kits		

1CN Series Handles

Add handles to your Keysight products for easier maneuvering and lifting

Order a front handle kit when your instrument does not come with pre-installed handles. Check to make sure your instrument requires handles, as many instruments are supplied with previously installed handles.

- Flanges attach to pre-existing holes in the instrument case.
- A plastic trim strip is easily removed and the handle or flange attaches with screws supplied in the kit.
- Before rack mounting, bottom feet must be removed.

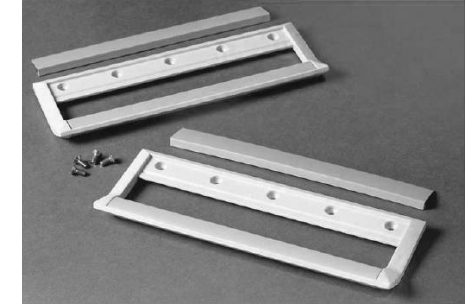

Instrument module height	Front handle kit (order new product if available)	New handle product (currently available, if populated)
88.1 mm (3.5 in)	5063-9226	1CN006A
132.6 mm (5.25 in)	5063-9227	1CN007A
177.0 mm (7.0 in)	5063-9228	1CN003A
221.5 mm (8.75 in)	5063-9229	1CN005A
265.9 mm (10.5 in)	5063-9230	1CN020A
Kit includes	2 handles, 2 trim strips, metric fasteners	

Technical Specifications

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
105B	105B-908	5060-8739	02	–	Contact parts ID	–	–	–	–	Contact parts ID
11713B	11713B-908	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
11713B	11713B-909	5063-9212	2863	–	1CM007A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link for side-by-side mount
11713C	11713C-908	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
11713C	11713C-909	5063-9212	2863	–	1CM007A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link for side-by-side mount
11757B	11757B-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
11757B	11757B-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
11758B	11758B-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
11758B	11758B-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
11759C	11759C-907	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
11759C	11759C-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
11759C	11759C-909	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
11759D	11759D-907	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
11759D	11759D-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
11759D	11759D-909	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
11896A	11896A-1CM	5063-9212	B1	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
11896A	11896A-1CN	5063-9226	B1	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
11896A	11896A-1CP	5063-9219	B1	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
11980A	11980A-907	5063-9226	B1	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
11980A	11980A-908	5063-9240	B1	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
16700B	16700B-1CM	5063-9216	08L	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
16701B	16701B-1CM	5063-9216	08L	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
1670G	1670G-1CM	5063-2157	08L	–	5063-2157	–	–	–	–	Rackmount kit
1671G	1671G-1CM	5063-2157	08L	–	5063-2157	–	–	–	–	Rackmount kit
1672G	1672G-1CM	5063-2157	08L	–	5063-2157	–	–	–	–	Rackmount kit
1673G	1673G-1CM	5063-2157	08L	–	5063-2157	–	–	–	–	Rackmount kit
1680A	1680A-1CM	01680-60002	08L	–	01680-60002	–	–	–	–	Metal-raw material
1680AD	1680AD-1CM	01680-60002	08L	–	01680-60002	–	–	–	–	Metal-raw material
1681A	1681A-1CM	01680-60002	08L	–	01680-60002	–	–	–	–	Metal-raw material
1681AD	1681AD-1CM	01680-60002	08L	–	01680-60002	–	–	–	–	Metal-raw material
1682A	1682A-1CM	01680-60002	08L	–	01680-60002	–	–	–	–	Metal-raw material
1682AD	1682AD-1CM	01680-60002	08L	–	01680-60002	–	–	–	–	Metal-raw material
1683A	1683A-1CM	01680-60002	08L	–	01680-60002	–	–	–	–	Metal-raw material
1683AD	1683AD-1CM	01680-60002	08L	–	01680-60002	–	–	–	–	Metal-raw material
1690A	1690A-1CM	5063-9214	08L	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
1690AD	1690AD-1CM	5063-9214	08L	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
1691A	1691A-1CM	5063-9214	08L	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
1691AD	1691AD-1CM	5063-9214	08L	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
1692A	1692A-1CM	5063-9214	08L	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
1692AD	1692AD-1CM	5063-9214	08L	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
1693A	1693A-1CM	5063-9214	08L	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
1693AD	1693AD-1CM	5063-9214	08L	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
33120A	33120A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
33210A	33210A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
33210A	33210A-1CN	5063-9212	09	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit
33220A	33220A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
33220A	33220A-1CN	5063-9212	09	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit
33250A	33250A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
33250A	33250A-1CN	5063-9212	09	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit
33502A	33502A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
33502A	33502A-1CN	5063-9212	09	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit
33521A	33521A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
33521A	33521A-1CN	5063-9212	09	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit
33522A	33522A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
33522A	33522A-1CN	5063-9212	09	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
34401A	34401A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
34405A	34405A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
34410A	34410A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
34410A	34410A-1CN	5063-9212	09	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit
34411A	34411A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
34411A	34411A-1CN	5063-9212	09	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit
34420A	34420A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
3457A	3457A-907	5062-5380	09	5062-5380	–	–	–	–	–	907 Front handle kit
3458A	3458A-907	5063-9226	09	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
3458A	3458A-908	5063-9212	09	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
3458A	3458A-909	5063-9219	09	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
3488A	3488A-907	5062-5380	Y500	5062-5380	–	–	–	–	–	907 front handle kit
34970A	34970A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
34972A	34972A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
34980A	Y1130A	Y1130A	MODS	–	Y1130A	–	–	–	–	Rackmount kit for 34980A, forward or reverse mount in standard 19-in rack; rail kit required: E3663AC forward, E3664AC reverse
3499A	3499A-1CM	5183-7171	2863	–	1CM029A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
3499A	3499A-1CP	5183-7170	2863	–	–	–	–	1CP016A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
3499B	3499B-1CM	5183-7172	2863	–	–	–	1CM032A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
35670A	35670A-AX4	5061-8064	2863	–	1CM069A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
35670U	35670U-AX4	5061-8064	2863	–	1CM069A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
4142B	4142B-907	5062-3991	33H	Contact parts ID	–	–	–	–	–	Contact parts ID
4142B	4142B-908	5063-9216	33H	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
4142B	4142B-909	5062-3985	33H	–	–	–	–	5062-3985	–	Rack flange and front handle kit
41501B	41501B-1CM	5063-9215	33H	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
4155C	4155C-1CM	5063-9216	33H	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
4263B	4263B-1CM	5063-9241	33	–	–	–	1CM019A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one quarter-module flange
4263B	4263B-1CN	5063-9226	33	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
4268A	4268A-1CM	5063-9241	33	–	–	–	1CM019A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one quarter-module flange
4268A	4268A-1CN	5063-9226	33	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
4279A	4279A-907	5062-3990	33	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
4279A	4279A-908	5062-3978	33	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
4279A	4279A-909	5062-3984	33	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
42841A	42841A-907	5062-3990	33	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
42841A	42841A-908	5062-3978	33	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
42841A	42841A-909	5062-3984	33	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
4284A	4284A-907	5062-3990	33	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
4284A	4284A-908	5062-3978	33	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
4284A	4284A-909	5062-3984	33	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
4285A	4285A-907	5062-3990	33	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
4285A	4285A-908	5062-3978	33	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
4285A	4285A-909	5062-3984	33	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
4287A	4287A-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
4287A	4287A-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
4287A	4287A-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
4288A	4288A-1CM	5063-9241	33	–	–	–	1CM019A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one quarter-module flange
4288A	4288A-1CN	5063-9226	33	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
4291B	4291B-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
4291B	4291B-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
4291B	4291B-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
4294A	4294A-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
4294A	4294A-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
4294A	4294A-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
4338B	4338B-1CM	5063-9241	33	–	–	–	1CM019A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one quarter-module flange
4338B	4338B-1CN	5063-9226	33	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
4339B	4339B-1CM	5063-9241	33	–	–	–	1CM019A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one quarter-module flange
4339B	4339B-1CN	5063-9226	33	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
4349B	4349B-1CM	5063-9241	33	–	–	–	1CM019A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one quarter-module flange
4349B	4349B-1CN	5063-9226	33	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
43521A	43521A-1CM	5063-9212	33	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
43521A	43521A-1CN	5063-9226	33	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
43521A	43521A-1CP	5063-9219	33	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
4352B	4352B-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
4352B	4352B-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
4352B	4352B-1CP	5063-9223	33	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
4395A	4395A-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
4395A	4395A-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
4395A	4395A-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
4396B	4396B-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
4396B	4396B-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
4396B	4396B-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
5071A	5071A-908	5062-3977	02	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
5071A	5071A-913	5062-4071	02	–	–	5062-4071	–	–	–	Rackmount kit
5087A	5087A-908	5060-8739	02	–	Contact parts ID	–	–	–	–	Contact parts ID
5089A	5089A-908	5062-3978	02	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
5089A	5089A-913	5062-4072	02	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
53131A	53131A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
53132A	53132A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
53147A	53147A-1CM	53147-67001	09	–	53147-67001	–	–	–	–	Rackmount kit
53148A	53148A-1CM	53147-67001	09	–	53147-67001	–	–	–	–	Rackmount kit
53149A	53149A-1CM	53147-67001	09	–	53147-67001	–	–	–	–	Rackmount kit
53150A	53150A-1CM	53150-67001	09	–	–	–	53150-67001	–	–	Sgt rackmount
53151A	53151A-1CM	53150-67001	09	–	–	–	53150-67001	–	–	Sgt rackmount
53152A	53152A-1CM	53150-67001	09	–	–	–	53150-67001	–	–	Sgt rackmount

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
53181A	53181A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
53210A	53210A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
53210A	53210A-1CN	5063-9212	09	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit
53220A	53220A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
53220A	53220A-1CN	5063-9212	09	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit
53230A	53230A-1CM	5063-9240	09	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
53230A	53230A-1CN	5063-9212	09	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit
54621A	54621A-1CM	5062-7345	08	–	5062-7345	–	–	–	–	Rackmount kit
54621D	54621D-1CM	5062-7345	08	–	5062-7345	–	–	–	–	Rackmount kit
54622A	54622A-1CM	5062-7345	08	–	5062-7345	–	–	–	–	Rackmount kit
54622D	54622D-1CM	5062-7345	08	–	5062-7345	–	–	–	–	Rackmount kit
54624A	54624A-1CM	5062-7345	08	–	5062-7345	–	–	–	–	Rackmount kit
54641A	54641A-1CM	5062-7345	08	–	5062-7345	–	–	–	–	Rackmount kit
54641D	54641D-1CM	5062-7345	08	–	5062-7345	–	–	–	–	Rackmount kit
54642A	54642A-1CM	5062-7345	08	–	5062-7345	–	–	–	–	Rackmount kit
54642D	54642D-1CM	5062-7345	08	–	5062-7345	–	–	–	–	Rackmount kit
54810A	54810A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54815A	54815A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54820A	54820A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54825A	54825A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54830B	54830B-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54830D	54830D-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54831B	54831B-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54831D	54831D-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
54832B	54832B-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54832D	54832D-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54833A	54833A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54833D	54833D-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54835A	54835A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54845A	54845A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54845B	54845B-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54846A	54846A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54846B	54846B-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54852A	54852A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54853A	54853A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54854A	54854A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
54855A	54855A-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
6010A	6010A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6010A	6010A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6011A	6011A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6011A	6011A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6012B	6012B-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6012B	6012B-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6015A	6015A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6015A	6015A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6030A	6030A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6030A	6030A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
6031A	6031A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6031A	6031A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6032A	6032A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6032A	6032A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6033A	6033A-800	5062-3978	21	–	1CM034A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
6033A	6033A-908	5062-3960	21	–	–	–	1CM001A	–	–	Rackmount flange kit 177.0 mm H (4U) - one flange, one half-module flange
6035A	6035A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6035A	6035A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6038A	6038A-800	5062-3978	21	–	1CM034A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
6038A	6038A-908	5062-3960	21	–	–	–	1CM001A	–	–	Rackmount flange kit 177.0 mm H (4U) - one flange, one half-module flange
6060B	6060B-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6060B	6060B-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6063B	6063B-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6063B	6063B-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6541A	6541A-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6541A	6541A-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
6542A	6542A-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6542A	6542A-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6543A	6543A-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6543A	6543A-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6544A	6544A-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6544A	6544A-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6545A	6545A-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6545A	6545A-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6551A	6551A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6551A	6551A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6552A	6552A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6552A	6552A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6553A	6553A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6553A	6553A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6554A	6554A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
6554A	6554A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6555A	6555A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6555A	6555A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6571A	6571A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6571A	6571A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6572A	6572A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6572A	6572A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6573A	6573A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6573A	6573A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6574A	6574A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6574A	6574A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6575A	6575A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6575A	6575A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
66000A	66000A-908	5062-3978	21	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
66000A	66000A-909	5062-3984	21	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
6611C	6611C-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
6611C	6611C-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole spacing; side-by-side mounting
6612C	6612C-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
6612C	6612C-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting
6613C	6613C-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
6613C	6613C-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting
6614C	6614C-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
6614C	6614C-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting
6621A	6621A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6621A	6621A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6622A	6622A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6622A	6622A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6623A	6623A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6623A	6623A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6624A	6624A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
6624A	6624A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6625A	6625A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6625A	6625A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6626A	6626A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6626A	6626A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6627A	6627A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6627A	6627A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6628A	6628A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6628A	6628A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6629A	6629A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6629A	6629A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
66309B	66309B-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
66309B	66309B-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting
66309D	66309D-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
66309D	66309D-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
66311B	66311B-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
66311B	66311B-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting
66311D	66311D-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
66311D	66311D-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting
66312A	66312A-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
66312A	66312A-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting
66319B	66319B-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
66319B	66319B-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting
66319D	66319D-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
66319D	66319D-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting
6631B	6631B-1CM	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6631B	6631B-1CP	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
66321B	66321B-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
66321B	66321B-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting
66321D	66321D-1CM	5062-3972	21	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
66321D	66321D-AXS	5062-3974	21	–	1CM021A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - 1.75 in hole space, side-by-side mounting
6632B	6632B-1CM	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6632B	6632B-1CP	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
66332A	66332A-1CM	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
66332A	66332A-1CP	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6633B	6633B-1CM	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6633B	6633B-1CP	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6634B	6634B-1CM	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6634B	6634B-1CP	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6641A	6641A-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6641A	6641A-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6642A	6642A-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6642A	6642A-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6643A	6643A-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6643A	6643A-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
6644A	6644A-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6644A	6644A-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6645A	6645A-908	5062-3974	21	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
6645A	6645A-909	5062-3975	21	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
6651A	6651A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6651A	6651A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6652A	6652A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6652A	6652A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6653A	6653A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6653A	6653A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6654A	6654A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6654A	6654A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6655A	6655A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6655A	6655A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6671A	6671A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
6671A	6671A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6672A	6672A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6672A	6672A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6673A	6673A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6673A	6673A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6674A	6674A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6674A	6674A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6675A	6675A-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6675A	6675A-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6680A	6680A-908	5062-3977	21	–	1CM028A	–	–	–	–	Rackmount flange kit 88.1 mm H (3U) and 132.6 mm H (2U) - 4 flanges (5U total)
6680A	6680A-909	5062-3975	21	–	–	–	–	1CP014A	–	Double Rackmount flange and handle kit 88.1 mm (2U) and 132.6 mm H (3U) - four flanges and handles (5U total)
6681A	6681A-908	5062-3977	21	–	1CM028A	–	–	–	–	Rackmount flange kit 88.1 mm H (3U) and 132.6 mm H (2U) - 4 flanges (5U total)
6681A	6681A-909	5062-3975	21	–	–	–	–	1CP014A	–	Double Rackmount flange and handle kit 88.1 mm (2U) and 132.6 mm H (3U) - four flanges and handles (5U total)
6682A	6682A-908	5062-3977	21	–	1CM028A	–	–	–	–	Rackmount flange kit 88.1 mm H (3U) and 132.6 mm H (2U) - 4 flanges (5U total)

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
6682A	6682A-909	5062-3975	21	–	–	–	–	1CP014A	–	Double Rackmount flange and handle kit 88.1 mm (2U) and 132.6 mm H (3U) - four flanges and handles (5U total)
6683A	6683A-908	5062-3977	21	–	1CM028A	–	–	–	–	Rackmount flange kit 88.1 mm H (3U) and 132.6 mm H (2U) - 4 flanges (5U total)
6683A	6683A-909	5062-3975	21	–	–	–	–	1CP014A	–	Double Rackmount flange and handle kit 88.1 mm (2U) and 132.6 mm H (3U) - four flanges and handles (5U total)
6684A	6684A-908	5062-3977	21	–	1CM028A	–	–	–	–	Rackmount flange kit 88.1 mm H (3U) and 132.6 mm H (2U) - 4 flanges (5U total)
6684A	6684A-909	5062-3975	21	–	–	–	–	1CP014A	–	Double Rackmount flange and handle kit 88.1 mm (2U) and 132.6 mm H (3U) - four flanges and handles (5U total)
6690A	6690A-908	5062-3977	21	–	1CM028A	–	–	–	–	Rackmount flange kit 88.1 mm H (3U) and 132.6 mm H (2U) - 4 flanges (5U total)
6690A	6690A-909	5062-3975	21	–	–	–	–	1CP014A	–	Double Rackmount flange and handle kit 88.1 mm (2U) and 132.6 mm H (3U) - four flanges and handles (5U total)
6691A	6691A-908	5062-3977	21	–	1CM028A	–	–	–	–	Rackmount flange kit 88.1 mm H (3U) and 132.6 mm H (2U) - 4 flanges (5U total)
6691A	6691A-909	5062-3975	21	–	–	–	–	1CP014A	–	Double Rackmount flange and handle kit 88.1 mm (2U) and 132.6 mm H (3U) - four flanges and handles (5U total)
6692A	6692A-908	5062-3977	21	–	1CM028A	–	–	–	–	Rackmount flange kit 88.1 mm H (3U) and 132.6 mm H (2U) - 4 flanges (5U total)
6692A	6692A-909	5062-3975	21	–	–	–	–	1CP014A	–	Double Rackmount flange and handle kit 88.1 mm (2U) and 132.6 mm H (3U) - four flanges and handles (5U total)
6811B	6811B-1CM	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6811B	6811B-1CP	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
6812B	6812B-1CM	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6812B	6812B-1CP	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
6813B	6813B-1CM	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
6813B	6813B-1CP	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
70001A	70001A-810	5062-0781	45	–	–	–	–	–	5062-0781	Mainframe heavy duty rack slide kit
70001A	70001A-908	5062-3978	45	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
70001A	70001A-913	5062-4072	45	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
70004A	70004A-810	5062-0781	45	–	–	–	–	–	5062-7086 (1); 5062-0781 (1)	Rack slide kit; Mainframe heavy duty rack slide kit
70004A	70004A-908	5063-9216	45	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
70004A	70004A-913	5062-4073	45	–	–	5062-4073	–	–	–	Rackmount kit
71209A	71209A-810	5062-0781	45	–	–	–	–	–	5062-0781	Mainframe heavy duty rack slide kit
71210C	71210C-810	5062-0781	45	–	–	–	–	–	5062-7086 (1); 5062-0781 (2)	Rack slide kit; Mainframe heavy duty rack slide kit
71400C	71400C-908	5062-3978	B1	–	Contact parts ID	–	–	–	–	Contact parts ID
71400C	71400C-913	5062-4072	B1	–	–	1CM035A (1); 5062-4073 (1)	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles; Rackmount kit
71450B	71450B-1CM	5063-9216	230	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
71451B	71451B-1CM	5063-9216	230	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
71452B	71452B-1CM	5063-9216	230	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
71501D	71501D-908	5063-9216	45	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
71501D	71501D-913	5062-4073	45	–	–	5062-4073	–	–	–	Rackmount kit
71707A	71707A-908	5063-9216	45	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
71707A	71707A-913	5062-4073	45	–	–	5062-4073	–	–	–	Rackmount kit
71708A	71708A-908	5063-9216	45	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
71708A	71708A-913	5062-4073	45	–	–	5062-4073	–	–	–	Rackmount kit
71910A	71910A-810	5062-0781	45	–	–	–	–	–	5062-7086 (1); 5062-0781 (2)	Kit, Rack Slide; Mainframe heavy duty rack slide kit
81101A	81101A-1CM	5063-9212	B1	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
81101A	81101A-1CN	5063-9226	B1	1CN018A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
81101A	81101A-1CP	5063-9219	B1	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
81101A	81101A-1CR	1494-0059	B1	–	–	–	–	–	1494-0059	Rack slide kit non-tilting - for 345.5 mm and 421.6 mm depth cabinets
81104A	81104A-1CM	5063-9212	B1	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
81104A	81104A-1CN	5063-9226	B1	1CN018A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
81104A	81104A-1CP	5063-9219	B1	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
81104A	81104A-1CR	1494-0059	B1	–	–	–	–	–	1494-0059	Rack slide kit non-tilting - for 345.5 mm and 421.6 mm depth cabinets
8110A	8110A-1CM	5062-3974	B1	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
8110A	8110A-1CN	5063-9226	B1	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
8110A	8110A-1CP	5062-3975	B1	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
8110A	8110A-1CR	1494-0060	B1	–	–	–	–	–	1494-0060	Kit-slide, standard
81110A	81110A-1CM	5063-9212	B1	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
81110A	81110A-1CN	5063-9226	B1	1CN018A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
81110A	81110A-1CP	5063-9219	B1	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
81110A	81110A-1CR	1494-0059	B1	–	–	–	–	–	1494-0059	Rack slide kit non-tilting - for 345.5 mm and 421.6 mm depth cabinets
81130A	81130A-1CM	5063-9212	B1	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
81130A	81130A-1CN	5063-9226	B1	1CN018A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
81130A	81130A-1CP	5063-9219	B1	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
81130A	81130A-1CR	1494-0059	B1	–	–	–	–	–	1494-0059	Rack slide kit non-tilting - for 345.5 mm and 421.6 mm depth cabinets
81133A	81133A-1CP	5063-9221	B1	–	–	–	–	Contact parts ID	–	Contact parts ID
81134A	81134A-1CP	5063-9221	B1	–	–	–	–	Contact parts ID	–	Contact parts ID
8114A	8114A-1CM	5062-3977	B1	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8114A	8114A-1CN	5063-9227	B1	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8114A	8114A-1CP	5062-3983	B1	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8114A	8114A-1CR	1494-0060	B1	–	–	–	–	–	1494-0060	Kit-slide, standard
81180A	81180A-1CP	81180-62301	B1	–	–	–	–	Contact parts ID	–	Contact parts ID
8133A	8133A-1CM	5062-3977	B1	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8133A	8133A-1CN	5063-9227	B1	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8133A	8133A-1CP	5062-3983	B1	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8133A	8133A-1CR	1494-0060	B1	–	–	–	–	–	1494-0060	Kit-slide, standard
8163A	8163A-908	5063-9240	B1	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
8163B	8163B-1CM	5063-9240	B1	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
8164A	8164A-1CM	5063-9214	B1	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8164A	8164A-1CN	5063-9227	B1	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8164B	8164B-1CM	5063-9214	B1	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8164B	8164B-1CN	5063-9227	B1	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8166B	8166B-1CM	5063-9216	B1	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
8340B	8340B-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8340B	8340B-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83420A	83420A-908	5062-3976	45	–	5062-3976	–	–	–	–	Rackmount kit
83420A	83420A-913	5062-4069	45	–	–	1CM005A	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges for units with existing handles
83424A	83424A-908	5062-3976	45	–	5062-3976	–	–	–	–	Rackmount kit
83424A	83424A-913	5062-4069	45	–	–	1CM005A	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges for units with existing handles
83425A	83425A-908	5062-3976	45	–	5062-3976	–	–	–	–	Rackmount kit
83425A	83425A-913	5062-4069	45	–	–	1CM005A	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges for units with existing handles
83437A	83437A-1CM	5063-9212	B1	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
83437A	83437A-1CN	5063-9226	B1	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
83437A	83437A-1CP	5063-9219	B1	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
83438A	83438A-1CM	5063-9212	B1	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
83438A	83438A-1CN	5063-9226	B1	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
83438A	83438A-1CP	5063-9219	B1	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
83475B	83475B-908	5062-7345	230	–	5062-7345	–	–	–	–	Rackmount kit
83480A	83480A-907	54710-68703	230	54710-68703	–	–	–	–	–	Front handle kit
8350B	8350B-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8350B	8350B-913	5062-4071	53	–	–	5062-4071	–	–	–	Rackmount kit
83620A	83620A-908	5062-3978	230	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83620A	83620A-913	5062-4072	230	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83620B	83620B-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83620B	83620B-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83621A	83621A-908	5062-3978	45	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83621A	83621A-913	5062-4072	45	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83621B	83621B-908	5062-3978	45	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83621B	83621B-913	5062-4072	45	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83622A	83622A-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83622A	83622A-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83622B	83622B-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
83622B	83622B-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83623A	83623A-908	5062-3978	230	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83623A	83623A-913	5062-4072	230	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83623B	83623B-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83623B	83623B-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83623L	83623L-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83623L	83623L-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83624A	83624A-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83624A	83624A-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83624B	83624B-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83624B	83624B-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83630A	83630A-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83630A	83630A-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83630B	83630B-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83630B	83630B-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
83630L	83630L-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83630L	83630L-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83631A	83631A-908	5062-3978	45	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83631A	83631A-913	5062-4072	45	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83631B	83631B-908	5062-3978	45	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83631B	83631B-913	5062-4072	45	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83640A	83640A-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83640A	83640A-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83640B	83640B-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83640B	83640B-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83640L	83640L-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83640L	83640L-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83650A	83650A-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83650A	83650A-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83650B	83650B-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
83650B	83650B-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83650L	83650L-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83650L	83650L-913	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83651A	83651A-908	5062-3978	45	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83651A	83651A-913	5062-4072	45	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83651B	83651B-908	5062-3978	45	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
83651B	83651B-913	5062-4072	45	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
83711B	83711B-1CH	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
83711B	83711B-1CM	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
83711B	83711B-1CP	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
83711B	83711B-1CR	1494-0059	53	–	–	–	–	–	1494-0059	Rack slide kit non-tilting - for 345.5 mm and 421.6 mm depth cabinets
83712B	83712B-1CP	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
83712B	83712B-1CR	1494-0059	53	–	–	–	–	–	1494-0059	Rack slide kit non-tilting - for 345.5 mm and 421.6 mm depth cabinets
83731B	83731B-1CH	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
83731B	83731B-1CM	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
83731B	83731B-1CP	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
83731B	83731B-1CR	1494-0059	53	–	–	–	–	–	1494-0059	Rack slide kit non-tilting - for 345.5 mm and 421.6 mm depth cabinets
83732B	83732B-1CH	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
83732B	83732B-1CM	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
83732B	83732B-1CP	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
83732B	83732B-1CR	1494-0059	53	–	–	–	–	–	1494-0059	Rack slide kit non-tilting - for 345.5 mm and 421.6 mm depth cabinets
83751A	83751A-1CH	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
83751A	83751A-1CM	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
83751A	83751A-1CP	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
83751A	83751A-1CR	1494-0015	53	–	–	–	–	–	1494-0015	Slide kit for support shelf
83751B	83751B-1CH	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
83751B	83751B-1CM	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
83751B	83751B-1CP	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
83751B	83751B-1CR	1494-0015	53	–	–	–	–	–	1494-0015	Slide kit for support shelf
83752A	83752A-1CH	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
83752A	83752A-1CM	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
83752A	83752A-1CP	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
83752A	83752A-1CR	1494-0015	53	–	–	–	–	–	1494-0015	Slide kit for support shelf
83752B	83752B-1CH	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
83752B	83752B-1CM	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
83752B	83752B-1CP	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
83752B	83752B-1CR	1494-0015	53	–	–	–	–	–	1494-0015	Slide kit for support shelf
8444A	8444A-908	5060-8739	45	–	Contact parts ID	–	–	–	–	Contact parts ID
8449B	8449B-907	5063-9226	2863	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
8449B	8449B-908	5062-3972	2863	–	–	–	1CM024A	–	–	Rackmount flange kit 88.1 mm H (2U) - one flange, one half-module flange
85046A	85046A-908	5062-3976	2863	–	5062-3976	–	–	–	–	Rackmount kit
85046A	85046A-913	5062-4069	2863	–	–	1CM005A	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges for units with existing handles
85046B	85046B-908	5062-3976	2863	–	5062-3976	–	–	–	–	Rackmount kit
85046B	85046B-913	5062-4069	2863	–	–	1CM005A	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges for units with existing handles
85047A	85047A-908	5062-3976	B1	–	5062-3976	–	–	–	–	Rackmount kit
85047A	85047A-913	5062-4069	B1	–	–	1CM005A	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges for units with existing handles
8504B	8504B-1CM	5063-9215	45	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8504B	8504B-1CN	5063-9228	45	1CN003A (2)	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
8504B	8504B-1CP	5063-9222	45	–	–	–	–	1CP005A (2)	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
85060C	85060C-913	5062-4069	B1	–	–	1CM005A	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges for units with existing handles
8509A	8509A-1CM	5063-9214	B1	–	34192A (2)	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
8509A	8509A-1CN	5063-9227	B1	1CN007A (2)	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8509A	8509A-1CP	5063-9221	B1	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8509B	8509B-1CM	5063-9214	B1	–	34192A (2)	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8509B	8509B-1CN	5063-9227	B1	1CN007A (2)	1CP008A (2)	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles; Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8509C	8509C-1CM	5063-9214	45	–	34192A (2)	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8509C	8509C-1CN	5063-9227	45	1CN007A (2)	1CP008A (2)	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles; Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8511A	8511A-908	5062-3977	45	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8511A	8511A-913	5062-4071	45	–	–	5062-4071	–	–	–	Rackmount kit
8511B	8511B-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8511B	8511B-913	5062-4071	53	–	–	5062-4071	–	–	–	Rackmount kit
8514B	8514B-908	5062-3977	45	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8514B	8514B-913	5062-4071	45	–	–	5062-4071	–	–	–	Rackmount kit
8515A	8515A-908	5062-3977	45	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8515A	8515A-913	5062-4071	45	–	–	5062-4071	–	–	–	Rackmount kit
8517A	8517A-908	5062-3977	45	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8517A	8517A-913	5062-4071	45	–	–	5062-4071	–	–	–	Rackmount kit
8517B	8517B-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8517B	8517B-913	5062-4071	53	–	–	5062-4071	–	–	–	Rackmount kit
85309A	85309A-908	5063-9214	45	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
85309A	85309A-913	5063-9221	45	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
85309B	85309B-1CM	5063-9214		–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
85309B	85309B-1CP	5063-9221		–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8530A	8530A-908	5062-3977	53	–	1CM003A (1); 1CM023A (1)	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flange flange; Rackmount flange kit 177.0 mm H (4U) - two flanges
8530A	8530A-913	5062-4072	53	–	–	5062-4071 (1); 1CM035A (1)	–	–	–	Rackmount kit; Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
85310A	85310A-908	5063-9214	45	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
85310A	85310A-913	5063-9221	45	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
85330A	85330A-913	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
85420E	85420E-1CM	5062-4071	45	–	–	5062-4071	–	–	–	Rackmount kit
85422E	85422E-1CM	5062-4073	45	–	–	5062-4073	–	–	–	Rackmount kit
85460A	85460A-1CM	5062-4071	230	–	–	5062-4071	–	–	–	Rackmount kit
85462A	85462A-1CM	5062-4073	53	–	–	5062-4073	–	–	–	Rackmount kit
85523A	85523A-1CM	5063-9212	53	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
85523A	85523A-1CN	5063-9226	53	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
85523A	85523A-1CP	5063-9219	53	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
8560E	8560E-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8560E	8560E-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8560EC	8560EC-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8560EC	8560EC-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8560EC	8560EC-C90	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
8560EC	8560EC-C91	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8560U	8560U-C90	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8560U	8560U-C91	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8561E	8561E-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8561E	8561E-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8561EC	8561EC-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8561EC	8561EC-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8562E	8562E-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8562E	8562E-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8562EC	8562EC-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8562EC	8562EC-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8562EC	8562EC-C90	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8562EC	8562EC-C91	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8562U	8562U-C90	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8562U	8562U-C91	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8563A	8563A-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8563A	8563A-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8563E	8563E-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8563E	8563E-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8563EC	8563EC-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8563EC	8563EC-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8563EC	8563EC-C90	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8563EC	8563EC-C91	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8563U	8563U-C90	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8563U	8563U-C91	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8564E	8564E-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8564E	8564E-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8564EC	8564EC-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8564EC	8564EC-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8564EC	8564EC-C90	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8564EC	8564EC-C91	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8564U	8564U-C90	5062-4840	45	–	–	–	–	5062-4840	–	Rackmount kit
8564U	8564U-C91	5062-4841	45	–	5062-4841	–	–	–	–	Rackmount kit without handles
85650A	85650A-908	5062-3974	53	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
85650A	85650A-913	5062-4069	53	–	–	1CM005A	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges for units with existing handles
8565E	8565E-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8565E	8565E-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8565EC	8565EC-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8565EC	8565EC-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8565EC	8565EC-C90	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8565EC	8565EC-C91	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8565U	8565U-C90	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8565U	8565U-C91	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
85660B	85660B-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
85660B	85660B-913	5062-4071	53	–	–	5062-4071	–	–	–	Rackmount kit
85662A	85662A-908	5062-3977	53	–	1CM003A (1); 85662-60229 (1)	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges; Kit rack mt pnl
85662A	85662A-913	5062-4071	53	–	–	5062-4071 (1); 85662-60229 (1)	–	–	–	Rackmount kit; Kit rack mt pnl
85670A	85670A-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
85670A	85670A-913	5062-4071	53	–	–	5062-4071	–	–	–	Rackmount kit
85680B	85680B-908	5062-3977	45	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
85680B	85680B-913	5062-4071	45	–	–	5062-4071	–	–	–	Rackmount kit
85685A	85685A-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
85685A	85685A-913	5062-4071	53	–	–	5062-4071	–	–	–	Rackmount kit
8590L	8590L-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8590L	8590L-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8591C	8591C-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8591C	8591C-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8591E	8591E-908	5062-4841	45	–	5062-4841	–	–	–	–	Rackmount kit without handles
8591E	8591E-909	5062-4840	45	–	–	–	–	5062-4840	–	Rackmount kit
8591EM	8591EM-908	5062-4841	230	–	5062-4841	–	–	–	–	Rackmount kit without handles
8591EM	8591EM-909	5062-4840	230	–	–	–	–	5062-4840	–	Rackmount kit
8592L	8592L-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
8592L	8592L-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8593E	8593E-908	5062-4841	45	–	5062-4841	–	–	–	–	Rackmount kit without handles
8593E	8593E-909	5062-4840	45	–	–	–	–	5062-4840	–	Rackmount kit
8593EM	8593EM-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8593EM	8593EM-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8594E	8594E-908	5062-4841	45	–	5062-4841	–	–	–	–	Rackmount kit without handles
8594E	8594E-909	5062-4840	45	–	–	–	–	5062-4840	–	Rackmount kit
8594EM	8594EM-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8594EM	8594EM-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8594L	8594L-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8594L	8594L-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8594Q	8594Q-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8594Q	8594Q-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8595E	8595E-908	5062-4841	45	–	5062-4841	–	–	–	–	Rackmount kit without handles
8595E	8595E-909	5062-4840	45	–	–	–	–	5062-4840	–	Rackmount kit
8595EM	8595EM-908	5062-4841	53	–	5062-4841	–	–	–	–	Rackmount kit without handles
8595EM	8595EM-909	5062-4840	53	–	–	–	–	5062-4840	–	Rackmount kit
8596E	8596E-908	5062-4841	45	–	5062-4841	–	–	–	–	Rackmount kit without handles
8596E	8596E-909	5062-4840	45	–	–	–	–	5062-4840	–	Rackmount kit
8596EM	8596EM-908	5062-4841	B1	–	5062-4841	–	–	–	–	Rackmount kit without handles
8596EM	8596EM-909	5062-4840	B1	–	–	–	–	5062-4840	–	Rackmount kit
86060C	86060C-1CN	5063-9220	B1	5063-9220	–	–	–	–	–	Rackmount kit - 88.1H with handle
86060C	86060C-1CP	5063-9221	B1	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
86061C	86061C-1CM	5062-3960	B1	–	–	–	1CM001A	–	–	Rackmount flange kit 177.0 mm H (4U) - one flange, one half-module flange
86061C	86061C-1CN	5063-9228	B1	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
86061C	86061C-1CP	5063-9222	B1	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
86062C	86062C-1CM	5063-9215	B1	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
86062C	86062C-1CN	5063-9228	B1	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
86062C	86062C-1CP	5063-9222	B1	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
86082A	86082A-1CN	5063-9227	230	1CN005A (1); 1CN007A (1)	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles; Handle kit 132.6 mm H (3U) - two front handles
86082A	86082A-AX4	5063-9214	230	–	34192A (1); 1CM015A (1)	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges; Rackmount flange kit 221.5 mm H (5U) - two flanges
86082A	86082A-AXE	5063-9223	230	–	–	–	–	1CP008A (1); 1CP020A (1)	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles; Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
86100A	86100A-AX4	86100-60030	45	–	1CM030A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86100A	86100A-AXE	86100-60031	45	–	–	–	–	1CP018A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
86100B	86100B-AX4	86100-60030	45	–	1CM030A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86100B	86100B-AXE	86100-60031	45	–	–	–	–	1CP018A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
86100C	86100C-AX4	86100-60030	45	–	1CM030A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86100C	86100C-AXE	86100-60031	45	–	–	–	–	1CP018A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
86100D	86100D-AX4	5063-9216	B1	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86100D	86100D-AXE	5063-9223	B1	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
86122A	86122A-1CM	5063-9214	45	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
86122A	86122A-1CN	5063-9227	45	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
86122A	86122A-1CP	5063-9221	45	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
86130A	86130A-AX4	86100-60030	230	–	1CM030A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86130A	86130A-AXE	86100-60031	230	–	–	–	–	1CP018A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
86140A	86140A-1CN	5063-9229	B1	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
86140A	86140A-AX4	5063-9216	B1	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86140A	86140A-AXE	5063-9236	B1	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
86140B	86140B-1CN	5063-9229	B1	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
86140B	86140B-AX4	5063-9216	B1	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86140B	86140B-AXE	5063-9236	B1	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
86141B	86141B-1CN	5063-9229	230	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
86141B	86141B-AX4	5063-9216	230	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86141B	86141B-AXE	5063-9236	230	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
86142A	86142A-1CN	5063-9229	B1	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
86142A	86142A-AX4	5063-9216	B1	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86142A	86142A-AXE	5063-9236	B1	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
86142B	86142B-1CN	5063-9229	B1	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
86142B	86142B-AX4	5063-9216	B1	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86142B	86142B-AXE	5063-9236	B1	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
86146B	86146B-1CN	5063-9229	53	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
86146B	86146B-AX4	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86146B	86146B-AXE	5063-9236	53	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8642A	8642A-907	5063-9227	230	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8642A	8642A-908	5062-3977	230	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8642A	8642A-909	5062-3983	230	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8642B	8642B-907	5063-9227	230	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8642B	8642B-908	5062-3977	230	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8642B	8642B-909	5062-3983	230	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8643A	8643A-907	5062-3990	53	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
8643A	8643A-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8643A	8643A-909	5062-3984	53	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
8644B	8644B-907	5062-3990	53	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
8644B	8644B-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
8644B	8644B-909	5062-3984	53	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
8645A	8645A-907	5062-3990	53	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
8645A	8645A-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8645A	8645A-909	5062-3984	53	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
8648A	8648A-1CM	08648-60001	53	–	08648-60001	–	–	–	–	Rackmount kit
8648B	8648B-1CM	08648-60001	53	–	08648-60001	–	–	–	–	Rackmount kit
8648C	8648C-1CM	08648-60001	53	–	08648-60001	–	–	–	–	Rackmount kit
8648D	8648D-1CM	08648-60001	53	–	08648-60001	–	–	–	–	Rackmount kit
8662A	8662A-907	5062-3990	53	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
8662A	8662A-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8662A	8662A-909	5062-3984	53	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
8663A	8663A-907	5062-3990	53	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
8663A	8663A-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8663A	8663A-909	5062-3984	53	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
8664A	8664A-907	5062-3990	230	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
8664A	8664A-908	5062-3978	230	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8664A	8664A-909	5062-3984	230	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
8665A	8665A-907	5062-3990	53	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
8665A	8665A-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
8665A	8665A-909	5062-3984	53	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
8665B	8665B-907	5062-3990	53	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
8665B	8665B-908	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8665B	8665B-909	5062-3984	53	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
8671B	8671B-907	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8671B	8671B-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8671B	8671B-909	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8672A	8672A-907	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8672A	8672A-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8672A	8672A-909	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8673B	8673B-907	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8673B	8673B-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8673B	8673B-909	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8673C	8673C-908	5062-3977	53	–	1CM028A	–	–	–	–	Rackmount flange kit 88.1 mm H (3U) and 132.6 mm H (2U) - 4 flanges (5U total)
8673C	8673C-913	5062-4073	53	–	–	5062-4073	–	–	–	Rackmount kit
8673D	8673D-908	5062-3977	53	–	1CM028A	–	–	–	–	Rackmount flange kit 88.1 mm H (3U) and 132.6 mm H (2U) - 4 flanges (5U total)
8673D	8673D-913	5062-4073	53	–	–	5062-4073	–	–	–	Rackmount kit

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
8673E	8673E-907	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8673E	8673E-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8673E	8673E-909	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8673G	8673G-907	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8673G	8673G-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8673G	8673G-909	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
8673H	8673H-907	5063-9227	45	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
8673H	8673H-908	5062-3977	45	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
8673H	8673H-909	5062-3983	45	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
86792A	86792A-907	5063-9229	53	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
86792A	86792A-908	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
86792A	86792A-909	5063-9223	53	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
8702B	8702B-908	5062-3978	230	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8702B	8702B-913	5062-4072	230	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
8702D	8702D-1CM	5063-9216	45	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8702D	8702D-1CP	5062-4073	45	–	–	5062-4073	–	–	–	Rackmount kit
8702E	8702E-1CM	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
8702E	8702E-1CP	5063-9236	53	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
87030A	87030A-1CM	5063-9232	230	–	–	5063-9232	–	–	–	Rackmount kit with handles 88.1 mm H (2U) - two flanges and handles
8703A	8703A-908	5063-9232	45	–	–	5063-9232 (1); 5063-9235 (1)	–	–	–	Rackmount kit with handles 88.1 mm H (2U) - two flanges and handles; Rackmount fkit with handles 177.0 mm H (4U) - two flanges and handles
8703B	8703B-908	5063-9212	53	–	34191A (1); 1CM015A (1)	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; Rackmount flange kit 221.5 mm H (5U) - two flanges
8703B	8703B-913	5063-9236	53	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
87050A	87050A-908	5062-3974	53	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
87050E	87050E-1CM	5063-9214	53	–	Contact parts ID	–	–	–	–	Contact parts ID
87075C	87075C-1CM	5063-9214	230	–	Contact parts ID	–	–	–	–	Contact parts ID
8711C	8711C-1CM	08712-60036	230	–	08712-60036	–	–	–	–	Rackmount kit with handles
8712C	8712C-1CM	08712-60036	53	–	08712-60036	–	–	–	–	Rackmount kit with handles
8712ES	8712ES-1CM	08712-60036	53	–	08712-60036	–	–	–	–	Rackmount kit with handles
8712ET	8712ET-1CM	08712-60036	230	–	08712-60036	–	–	–	–	Rackmount kit with handles
8713C	8713C-1CM	08712-60036	230	–	08712-60036	–	–	–	–	Rackmount kit with handles
8714C	8714C-1CM	08712-60036	53	–	08712-60036	–	–	–	–	Rackmount kit with handles
8714ES	8714ES-1CM	08712-60036	53	–	08712-60036	–	–	–	–	Rackmount kit with handles
8714ET	8714ET-1CM	08712-60036	230	–	08712-60036	–	–	–	–	Rackmount kit with handles
8719D	8719D-1CM	5063-9216	2863	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8719D	8719D-1CP	5063-9236	2863	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8719ES	8719ES-1CM	5063-9216	2863	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8719ES	8719ES-1CP	5063-9236	2863	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
8719ET	8719ET-1CM	5063-9216	230	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8719ET	8719ET-1CP	5063-9236	230	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8720D	8720D-1CM	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8720D	8720D-1CP	5063-9236	53	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8720ES	8720ES-1CM	5063-9216	2863	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8720ES	8720ES-1CP	5063-9236	2863	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8720ET	8720ET-1CM	5063-9216	230	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8720ET	8720ET-1CP	5063-9236	230	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8722D	8722D-1CM	5063-9216	2863	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8722D	8722D-1CP	5063-9236	2863	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8722ES	8722ES-1CM	5063-9216	2863	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8722ES	8722ES-1CP	5063-9236	2863	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8722ET	8722ET-1CM	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8722ET	8722ET-1CP	5063-9236	53	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8730A	8730A-1CM	08712-60036	33	–	08712-60036	–	–	–	–	Rackmount kit with handles
87511A	87511A-907	5063-9226	33	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
87511A	87511A-908	5062-3974	33	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
87511A	87511A-909	5062-3975	33	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
87511B	87511B-907	5063-9226	230	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
87511B	87511B-908	5062-3974	230	–	1CM002A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges; 1.75 in hole spacing
87511B	87511B-909	5062-3975	230	–	–	–	–	1CP001A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
8752C	8752C-1CM	5062-3978	53	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8752C	8752C-1CP	5062-4072	53	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
8753D	8753D-1CM	5063-9216	230	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8753D	8753D-1CP	5062-4073	230	–	–	5062-4073	–	–	–	Rackmount kit
8753E	8753E-1CM	5063-9216	2863	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8753E	8753E-1CP	5063-9236	2863	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8753ES	8753ES-1CM	5063-9216	2863	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8753ES	8753ES-1CP	5063-9236	2863	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8753ET	8753ET-1CM	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8753ET	8753ET-1CP	5063-9236	53	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles
8757C	8757C-908	5062-3978	2863	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
8757C	8757C-913	5062-4072	2863	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
8757D	8757D-908	5062-3978	230	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8757D	8757D-913	5062-4072	230	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
8757E	8757E-908	5062-3978	45	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
8757E	8757E-913	5062-4072	45	–	–	1CM035A	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges for units with existing handles
8770A	8770A-908	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
8770A	8770A-909	5063-9223	53	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
8780A	8780A-907	5062-3990	53	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
8780A	8780A-909	5062-3984	53	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
89410A	89410A-AX3	5063-9229	53	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
89410A	89410A-AX4	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
89410A	89410A-AX5	5063-9223	53	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
89431A	89431A-AX3	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
89431A	89431A-AX4	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
89431A	89431A-AX5	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
89441A	89441A-AX3	5063-9228	33H	1CN003A (1); 1CN005A (1)	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles; Handle kit 221.5 mm H (5U) - two front handles
89441A	89441A-AX5	5063-9222	33H	–	–	–	–	1CP005A (1); 1CP020A (1)	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles; Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
B1500A	B1500A-1CM	5063-9218	33H	–	1CM033A	–	–	–	–	Rackmount flange kit 355.6 mm H (8U) - two flanges
B2200A	B2200A-1CM	5063-9218	33H	–	1CM033A	–	–	–	–	Rackmount flange kit 355.6 mm H (8U) - two flanges
B2901A	B2901A-1CM	5063-9240	33H	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
B2902A	B2902A-1CM	5063-9240	33H	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
B2911A	B2911A-1CM	5063-9240	33H	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
B2912A	B2912A-1CM	5063-9240	08	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
DSA90254A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSA90404A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSA90604A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSA90804A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSA91204A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSA91304A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSAX91604A	DSOX90000-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
DSAX92004A	DSOX90000-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSAX92504A	DSOX90000-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSAX92804A	DSOX90000-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSAX93204A	DSOX90000-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSO80204B	DSO80000-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
DSO80304B	DSO80000-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
DSO80404B	DSO80000-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
DSO80604B	DSO80000-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
DSO80804A	DSO80000-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
DSO80804B	DSO80000-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
DSO81004A	DSO80000-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
DSO81004B	DSO80000-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
DSO81204A	DSO80000-1CM	E2609-60004	08	–	E2609B	–	–	–	–	Rackmount kit
DSO9000A	DSO9000A-1CM	N2902-60001 (1)	08	–	N2902-60001	–	–	–	–	Rackmount kit
DSO90254A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware - support shelf and hardware
DSO90404A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware - support shelf and hardware
DSO90604A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware - support shelf and hardware
DSO9064A	DSO9000A-1CM	N2902-60001	08	–	N2902A	–	–	–	–	Rackmount kit for 9000 Series oscilloscope - support shelf and hardware
DSO90804A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware - support shelf and hardware
DSO9104A	DSO9000A-1CM	N2902-60001	08	–	N2902A	–	–	–	–	Rackmount kit for 9000 Series oscilloscope - support shelf and hardware

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
DSO91204A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware - support shelf and hardware
DSO91304A	DSO90000A-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSO9254A	DSO9000A-1CM	N2902-60001	08	–	N2902A	–	–	–	–	Rackmount kit for 9000 Series oscilloscope - support shelf and hardware
DSO9404A	DSO9000A-1CM	N2902-60001	08	–	N2902A	–	–	–	–	Rackmount kit for 9000 Series oscilloscope - support shelf and hardware
DSOX90000Q	DSOX90000Q-1CM	N2759-60001	08	–	N2759-60001	–	–	–	–	Rackmount kit
DSOX91604A	DSOX90000-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSOX92004A	DSOX90000-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSOX92504A	DSOX90000-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSOX92804A	DSOX90000-1CM	N5470-60001	08	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
DSOX93204A	DSOX90000-1CM	N5470-60001	MODS	–	N5470A	–	–	–	–	Rackmount kit for Infiniium DSO90000 Series - support shelf and hardware
E1300B	E1300B-907	5062-3990	MODS	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
E1301B	E1301B-907	5062-3990	2863	1CN012A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
E1401B	E1401B-AX3	5062-3993	2863	Contact parts ID	–	–	–	–	–	Contact parts ID
E1401B	E1401B-AX5	5062-3987	2863	–	–	–	–	Contact parts ID	–	Contact parts ID
E3614A	E3614A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E3615A	E3615A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E3616A	E3616A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E3617A	E3617A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E3620A	E3620A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E3631A	E3631A-1CM	5063-9243	2863	–	–	–	34193A	–	–	Rackmount flange kit 132.6 mm H (3U) - one flange, one half-module flange
E3632A	E3632A-1CM	5063-9243	2863	–	–	–	34193A	–	–	Rackmount flange kit 132.6 mm H (3U) - one flange, one half-module flange
E3632A	E3632A-1CP	5063-9214	2863	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E3633A	E3633A-1CM	5063-9243	2863	–	–	–	34193A	–	–	Rackmount flange kit 132.6 mm H (3U) - one flange, one half-module flange
E3634A	E3634A-1CM	5063-9243	2863	–	–	–	34193A	–	–	Rackmount flange kit 132.6 mm H (3U) - one flange, one half-module flange
E3640A	E3640A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E3641A	E3641A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E3642A	E3642A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E3643A	E3643A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E3644A	E3644A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E3645A	E3645A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E3646A	E3646A-1CM	5063-9243	2863	–	–	–	34193A	–	–	Rackmount flange kit 132.6 mm H (3U) - one flange, one half-module flange
E3647A	E3647A-1CM	5063-9243	2863	–	–	–	34193A	–	–	Rackmount flange kit 132.6 mm H (3U) - one flange, one half-module flange

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E3648A	E3648A-1CM	5063-9243	2863	–	–	–	34193A	–	–	Rackmount flange kit 132.6 mm H (3U) - one flange, one half-module flange
E3649A	E3649A-1CM	5063-9243	21	–	–	–	34193A	–	–	Rackmount flange kit 132.6 mm H (3U) - one flange, one half-module flange
E4350B	E4350B-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4350B	E4350B-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4351B	E4351B-908	5062-3977	21	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4351B	E4351B-909	5062-3983	21	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4356A	E4356A-908	5062-3977	53	–	1CM003A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4356A	E4356A-909	5062-3983	53	–	–	–	–	1CP002A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4400A	E4400A-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4400A	E4400A-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4400A	E4400A-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4400B	E4400B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4400B	E4400B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4400B	E4400B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4401B	E4401B-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4401BU	E4401BU-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4402B	E4402B-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4402B	E5505A-RK4	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4402BU	E4402BU-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4403B	E4403B-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E4403BU	E4403BU-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4404B	E4404B-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4405B	E4405B-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4406A	E4406A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4406A	E4406A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4406A	E4406A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4406A	E4406A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4407B	E4407B-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4407BU	E4407BU-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4408B	E4408B-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4408BU	E4408BU-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4411A	E4411A-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4411AU	E4411AU-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4411B	E4411B-1CP	E4401-60385	53	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4411B	E5505A-RK3	E4401-60385	2863	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4411BU	E4411BU-1CP	E4401-60385	2863	–	–	–	–	E4401-60385	–	Rackmount kit with handles
E4416A	E4416A-908	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E4416A	E4416A-909	5063-9212	2863	–	1CM007A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link for side-by-side mount
E4417A	E4417A-908	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E4418B	E4418B-908	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
E4418B	E4418B-909	5063-9212	2863	–	1CM007A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link for side-by-side mount
E4419B	E4419B-908	5063-9240	53	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E4419B	E4419B-909	5063-9212	53	–	1CM007A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link for side-by-side mount
E4420A	E4420A-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4420A	E4420A-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4420A	E4420A-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4420B	E4420B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4420B	E4420B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4420B	E4420B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4421A	E4421A-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4421A	E4421A-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4421A	E4421A-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4421B	E4421B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4421B	E4421B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4421B	E4421B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4422A	E4422A-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4422A	E4422A-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4422A	E4422A-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E4422B	E4422B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4422B	E4422B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4422B	E4422B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4423B	E4423B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4423B	E4423B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4423B	E4423B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4424B	E4424B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4424B	E4424B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4424B	E4424B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4425B	E4425B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4425B	E4425B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4425B	E4425B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4426B	E4426B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4426B	E4426B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4426B	E4426B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4428C	E4428C-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4428C	E4428C-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E4428C	E4428C-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4430A	E4430A-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4430A	E4430A-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4430A	E4430A-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4430B	E4430B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4430B	E4430B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4430B	E4430B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4431A	E4431A-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4431A	E4431A-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4431A	E4431A-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4431B	E4431B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4431B	E4431B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4431B	E4431B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4432A	E4432A-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4432A	E4432A-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4432A	E4432A-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E4432B	E4432B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4432B	E4432B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4432B	E4432B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4433A	E4433A-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4433A	E4433A-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4433A	E4433A-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4433B	E4433B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4433B	E4433B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4433B	E4433B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4434B	E4434B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4434B	E4434B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4434B	E4434B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4435B	E4435B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4435B	E4435B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4435B	E4435B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4436B	E4436B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4436B	E4436B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E4436B	E4436B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4437B	E4437B-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4437B	E4437B-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4437B	E4437B-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4438C	E4438C-1CM	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E4438C	E4438C-1CN	5063-9227	53	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E4438C	E4438C-1CP	5063-9221	53	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E4440A	E4440A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4440A	E4440A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4440A	E4440A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4440A	E4440A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4440AU	E4440AU-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4440AU	E4440AU-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4440AU	E4440AU-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4440AU	E4440AU-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4443A	E4443A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4443A	E4443A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E4443A	E4443A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4443A	E4443A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4443AU	E4443AU-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4443AU	E4443AU-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4443AU	E4443AU-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4443AU	E4443AU-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4445A	E4445A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4445A	E4445A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4445A	E4445A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4445A	E4445A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4445AU	E4445AU-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4445AU	E4445AU-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4445AU	E4445AU-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4445AU	E4445AU-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4446A	E4446A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4446A	E4446A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4446A	E4446A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4446A	E4446A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4446AU	E4446AU-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E4446AU	E4446AU-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4446AU	E4446AU-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4446AU	E4446AU-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4447A	E4447A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4447A	E4447A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4447A	E4447A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4447A	E4447A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4447AU	E4447AU-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4447AU	E4447AU-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4447AU	E4447AU-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4447AU	E4447AU-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4448A	E4448A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4448A	E4448A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4448A	E4448A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4448A	E4448A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E4448AU	E4448AU-1CM	5063-9215	33	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E4448AU	E4448AU-1CN	5063-9228	33	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E4448AU	E4448AU-1CP	5063-9222	33	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E4448AU	E4448AU-1CR	E4406-60115	33	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E4980A	E4980A-1CM	5063-9241	33	–	–	–	1CM019A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one quarter-module flange
E4981A	E4981A-1CM	5063-9241	33	–	–	–	1CM019A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one quarter-module flange
E4982A	E4982A-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E4982A	E4982A-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E4982A	E4982A-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E4990A	E4990A-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E4990A	E4990A-1CN		33	1CN005A, E4490-20001	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E4990A	E4990A-1CP	5188-4430	33	–	–	–	–	1CP009A, E4490-20001	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E4991A	E4991A-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E4991A	E4991A-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E4991A	E4991A-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E4991B	E4991B-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E4991B	E4991B-1CN		33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E4991B	E4991B-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E5052A	E5052A-1CM	5063-9217	33	–	1CM042A	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges
E5052A	E5052A-1CN	5063-9230	33	1CN020A	–	–	–	–	–	Handle kit 265.9 mm H (6U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E5052A	E5052A-1CP	5063-9224	33	–	–	–	–	1CP019A	–	Rackmount flange and handle kit 265.9 mm H (6U) - two flanges and front handles
E5052B	E5052B-1CM	5063-9217	33	–	1CM042A	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges
E5052B	E5052B-1CN	5063-9230	33	1CN020A	–	–	–	–	–	Handle kit 265.9 mm H (6U) - two front handles
E5052B	E5052B-1CP	5063-9224	33	–	–	–	–	1CP019A	–	Rackmount flange and handle kit 265.9 mm H (6U) - two flanges and front handles
E5053A	E5053A-1CM	5063-9214	33	–	Contact parts ID	–	–	–	–	Contact parts ID
E5053A	E5053A-1CN	5063-9227	33	1CN007A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
E5053A	E5053A-1CP	5063-9221	33	–	–	–	–	Contact parts ID	–	Contact parts ID
E5061A	E5061A-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5061A	E5061A-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E5061A	E5061A-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E5061B	E5061B-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5061B	E5061B-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E5061B	E5061B-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E5062A	E5062A-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5062A	E5062A-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E5062A	E5062A-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E5063A	E5063A-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5063A	E5063A-1CN	5063-9229	33	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E5063A	E5063A-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount and front handle kit
E5070B	E5070B-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5070B	E5070B-1CN	5063-9229	33	–	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E5070B	E5070B-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E5070C	E5070C-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5070C	E5070C-1CN	5063-9229	33	–	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E5070C	E5070C-1CP	5063-9223	33	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E5071B	E5071B-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5071B	E5071B-1CN	5063-9229	33	–	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E5071B	E5071B-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E5071C	E5071C-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5071C	E5071C-1CN	5063-9229	33	–	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E5071C	E5071C-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E5072A	E5072A-1CM	5063-9216	33	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5072A	E5072A-1CN	5063-9229	33	–	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E5072A	E5072A-1CP	5188-4430	33	–	–	–	–	1CP009A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E5091A	E5091A-1CM	5063-9212	33	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E5091A	E5091A-1CN	5063-9226	33	–	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
E5091A	E5091A-1CP	5063-9219	33	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
E5092A	E5092A-1CM	5063-9214	33	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E5092A	E5092A-1CN	5063-9227	33	–	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles
N5193A	–	1CN107A	53	1CN107A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles Keysight color
N5191A	–	1CN107A	53	1CN107A	–	–	–	–	–	Handle kit 132.6 mm H (3U) - two front handles Keysight color
E5092A	E5092A-1CP	5063-9221	33	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
E5100A	E5100A-1CM	5062-3978	33	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E5100A	E5100A-1CN	5062-3990	33	–	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
E5100A	E5100A-1CP	5062-3984	33	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E5100B	E5100B-1CM	5062-3978	33H	–	1CM023A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E5100B	E5100B-1CN	5062-3990	33H	–	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles, System II plus
E5100B	E5100B-1CP	5062-3984	33H	–	–	–	–	1CP013A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E5250A	E5250A-1CM	5063-9216	33H	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5262A	E5262A-1CM	5063-9214	33H	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E5270B	E5270B-1CM	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5505A	E5505A-RK1	5063-9245	53	–	–	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - one flange, one half-module flange

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E5515B	E5515B-AX3	5063-9229	53	–	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E5515B	E5515B-AX4	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5515B	E5515B-AX5	5063-9223	53	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E5515C	E5515C-AX3	5063-9229	53	–	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E5515C	E5515C-AX4	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E5515C	E5515C-AX5	5063-9223	53	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E6601A	E6601A-AX3	5063-9229	53	–	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E6601A	E6601A-AX4	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E6601A	E6601A-AX5	5063-9223	53	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E6607A	E6607A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E6607A	E6607A-1CN	5063-9228	53	–	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E6607A	E6607A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E6607A	E6607A-1CR	E4406-60115	53	–	–	–	–	–	–	Rack slide kit non-tilting
E6607AK	E6607AK-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E6607AK	E6607AK-1CN	5063-9228	53	–	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E6607AK	E6607AK-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E6607AK	E6607AK-1CR	E4406-60115	53	–	–	–	–	–	–	Rack slide kit non-tilting
E6607B	E6607B-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E6607B	E6607B-1CN	5063-9228	53	–	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E6607B	E6607B-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E6607B	E6607B-1CR	E4406-60115	53	–	–	–	–	–	–	Rack slide kit non-tilting
E6607C	E6607C-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E6607C	E6607C-1CN	5063-9228	53	–	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E6607C	E6607C-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E6607C	E6607C-1CR	E4406-60115	53	–	–	–	–	–	–	Rack slide kit non-tilting
E6607CK	E6607CK-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount kit
E6607CK	E6607CK-1CN	5063-9228	53	5063-9228	–	–	–	–	–	Front handle kit
E6607CK	E6607CK-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E6607CK	E6607CK-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
E6620A	E6620A-1CM	5063-9216	10	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E6620A	E6620A-1CN	5063-9229	10	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
E6620A	E6620A-1CP	5063-9223	10	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E6640AU	E6640AU-1CP	E6640-60001	53	–	–	–	–	E6640-60001	–	–
E6640AU	E6640AU-1CR	E6640-60001	53	–	–	–	–	–	Contact parts ID	Contact parts ID
E6640AU	E6640AU-1CR	M9018-00001	MODS	–	–	–	–	–	Contact parts ID	Contact parts ID
E6650A	E6650A-1CP	E6640-60001	53	–	–	–	–	–	–	–
E6650A	E6650A-1CR	E6640-60001	53	–	–	–	–	–	Contact parts ID	Contact parts ID
E6650A	E6650A-1CR	M9018-00001	MODS	–	–	–	–	–	Contact parts ID	Contact parts ID
E6650AU	E6650AU-1CP	E6640-60001	53	–	–	–	–	–	–	–
E6650AU	E6650AU-1CR	E6640-60001	53	–	–	–	–	–	Contact parts ID	Contact parts ID
E6650AU	E6650AU-1CR	M9018-00001	MODS	–	–	–	–	–	Contact parts ID	Contact parts ID
E6900A	E6900A-AX3	5063-9229	53	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E6900A	E6900A-AX4	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
E6900A	E6900A-AX5	5063-9223	53	–	–	–	–	–	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
E7401A	E7401A-1CP	E4401-60385	53	–	–	–	–	–	–	Rackmount kit with handles
E7401AU	E7401AU-1CP	E4401-60385	53	–	–	–	–	–	–	Rackmount kit with handles
E7402A	E7402A-1CP	E4401-60385	53	–	–	–	–	–	–	Rackmount kit with handles
E7402AU	E7402AU-1CP	E4401-60385	53	–	–	–	–	–	–	Rackmount kit with handles
E7403A	E7403A-1CP	E4401-60385	53	–	–	–	–	–	–	Rackmount kit with handles
E7403AU	E7403AU-1CP	E4401-60385	53	–	–	–	–	–	–	Rackmount kit with handles
E7404A	E7404A-1CP	E4401-60385	53	–	–	–	–	–	–	Rackmount kit with handles
E7404AU	E7404AU-1CP	E4401-60385	53	–	–	–	–	–	–	Rackmount kit with handles
E7405A	E7405A-1CP	E4401-60385	53	–	–	–	–	–	–	Rackmount kit with handles
E7405AU	E7405AU-1CP	E4401-60385	53	–	–	–	–	–	–	Rackmount kit with handles
E7515A	E7515A-1CM	E7515-60021	AT4	–	E7515-60021	–	–	–	–	Rackmount flange kit - 2 flanges
E7515AU	E7515AU-1CM	E7515-60021	AT4	–	E7515-60021	–	–	–	–	Rackmount flange kit - 2 flanges
E8241A	E8241A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E8241A	E8241A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E8241A	E8241A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E8244A	E8244A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E8244A	E8244A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E8244A	E8244A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E8247C	E8247C-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E8247C	E8247C-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E8247C	E8247C-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E8251A	E8251A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E8251A	E8251A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E8251A	E8251A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E8254A	E8254A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E8254A	E8254A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E8254A	E8254A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E8257C	E8257C-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E8257C	E8257C-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E8257C	E8257C-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E8257D	E8257D-1CM	5063-9215	53	–	1CM014A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges, four hole plugs
E8257D	E8257D-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E8257D	E8257D-1CP	5063-9222	53	–	–	–	–	1CP006A	–	Rackmount flange and handle kit 177.0 mm H (4U) - flanges, handles, hole plugs
E8257N	E8257N-1CM	5063-9215	53	–	1CM014A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges, four hole plugs
E8257N	E8257N-1CP	5063-9222	53	–	–	–	–	1CP006A	–	Rackmount flange and handle kit 177.0 mm H (4U) - flanges, handles, hole plugs
E8267C	E8267C-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
E8267C	E8267C-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E8267C	E8267C-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
E8267D	E8267D-1CM	5063-9215	53	–	1CM014A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges, four hole plugs
E8267D	E8267D-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E8267D	E8267D-1CP	5063-9222	53	–	–	–	–	1CP006A	–	Rackmount flange and handle kit 177.0 mm H (4U) - flanges, handles, hole plugs
E8356A	E8356A-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
E8356A	E8356A-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
E8356B	E8356B-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
E8356B	E8356B-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
E8357A	E8357A-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
E8357A	E8357A-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
E8357B	E8357B-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
E8358A	E8358A-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
E8358A	E8358A-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
E8358B	E8358B-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
E8358B	E8358B-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E8361A	E8361A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
E8361A	E8361A-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
E8361C	E8361C-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
E8361C	E8361C-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
E8362A	E8362A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
E8362A	E8362A-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
E8362C	E8362C-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
E8362C	E8362C-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
E8363A	E8363A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
E8363A	E8363A-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
E8363C	E8363C-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
E8363C	E8363C-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
E8364A	E8364A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
E8364A	E8364A-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
E8364C	E8364C-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
E8364C	E8364C-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
E8663B	E8663B-1CM	5063-9215	53	–	1CM014A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges, four hole plugs
E8663B	E8663B-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E8663B	E8663B-1CP	5063-9222	53	–	–	–	–	1CP006A	–	Rackmount flange and handle kit 177.0 mm H (4U) - flanges, handles, hole plugs

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E8663D	E8663D-1CM	5063-9215	2863	–	1CM014A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges, four hole plugs
E8663D	E8663D-1CN	5063-9228	2863	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
E8663D	E8663D-1CP	5063-9222	2863	–	–	–	–	1CP006A	–	Rackmount flange and handle kit 177.0 mm H (4U) - flanges, handles, hole plugs
E8781A	E8781A-A83	5063-9214	53	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
E8781A	E8781A-A85	5063-9212	53	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
E8801A	E8801A-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
E8801A	E8801A-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
E8801B	E8801B-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
E8801B	E8801B-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
E8802A	E8802A-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
E8802A	E8802A-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
E8802B	E8802B-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
E8802B	E8802B-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
E8803A	E8803A-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
E8803A	E8803A-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
E8803B	E8803B-1CM	5063-9216	A1	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
E8803B	E8803B-1CP	5063-9236	A1	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
J7519A	J7519A-1CM	1530-2497	A1	–	Contact parts ID	–	–	–	–	Contact parts ID
J7519A	J7519A-1CR	E4270-60012	A1	–	–	–	–	–	E4270-60012	Rackmount kit - 19-inch for Intel Server
J7520A	J7520A-1CM	1530-2497	MODS	–	Contact parts ID	–	–	–	–	Contact parts ID
J7520A	J7520A-1CR	E4270-60012	MODS	–	–	–	–	–	E4270-60012	Rackmount kit - 19-inch for Intel Server
J7523A	J7523A-1CM	1530-2497	00	–	Contact parts ID	–	–	–	–	Contact parts ID
J7523A	J7523A-1CR	E4270-60012	A1	–	–	–	–	–	E4270-60012	Rackmount kit - 19-inch for Intel Server
L4490A	L4490A-AXA	5063-9212	MODS	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
L4490A	L4490A-AXB	5063-9219	MODS	–	–	–	–	1CP011A	–	Rackmount flange and handle kit 88.1 mm H (2U) - two flanges and front handles
L4490A	L4490A-AXC	1494-0059	MODS	–	–	–	–	–	1494-0059	Rack slide kit non-tilting - for 345.5 mm and 421.6 mm depth cabinets
L4491A	L4491A-AXA	5063-9215	MODS	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
L4491A	L4491A-AXB	5063-9222	MODS	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
L4491A	L4491A-AXC	1494-0059	MODS	–	–	–	–	–	1494-0059	Rack slide kit non-tilting - for 345.5 mm and 421.6 mm depth cabinets
L4532A	L4532A-908	L4532-67001	MODS	–	L4532-67001	–	–	–	–	Rackmount kit
L4534A	L4534A-908	L4532-67001	08	–	L4532-67001	–	–	–	–	Rackmount kit
MSO9064A	MSO9000A-1CM	N2902-60001	08	–	N2902A	–	–	–	–	Rackmount kit for 9000 Series oscilloscope - support shelf and hardware
MSO9104A	MSO9000A-1CM	N2902-60001	08	–	N2902A	–	–	–	–	Rackmount kit for 9000 Series oscilloscope - support shelf and hardware
MSO9254A	MSO9000A-1CM	N2902-60001	08	–	N2902A	–	–	–	–	Rackmount kit for 9000 Series oscilloscope - support shelf and hardware

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
MSO9404A	MSO9000A-1CM	N2902-60001	2863	–	N2902A	–	–	–	–	Rackmount kit for 9000 Series oscilloscope - support shelf and hardware
N1911A	N1911A-908	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
N1911A	N1911A-909	5063-9212	2863	–	1CM007A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link for side-by-side mount
N1912A	N1912A-908	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
N1912A	N1912A-909	5063-9212	2863	–	1CM007A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link for side-by-side mount
N1913A	N1913A-908	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
N1913A	N1913A-909	5063-9212	2863	–	1CM007A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link for side-by-side mount
N1914A	N1914A-908	5063-9240	53	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
N1914A	N1914A-909	5063-9212	53	–	1CM007A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link for side-by-side mount
N1996A	N1996A-1CM	5063-9215	53	–	1CM013A (1); N1996-60021 (1)	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges; kit, rear feet, system II
N1996AK	N1996AK-1CM	5063-9215	21	–	Contact parts ID	–	–	–	–	Contact parts ID
N1996AK	N1996AK-1CP	5063-9222	21	–	–	–	–	Contact parts ID	–	Contact parts ID
N3280A	N3280A-1CM	5063-9240	21	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
N3280A	N3280A-AXS	5063-9212	21	–	Contact parts ID	–	–	–	–	Contact parts ID
N3300A	N3300A-908	5062-3974	21	–	Contact parts ID	–	–	–	–	Contact parts ID
N3300A	N3300A-909	5062-3975	21	–	–	–	–	Contact parts ID	–	Contact parts ID
N3301A	N3301A-800	5062-3978	53	–	1CM034A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
N3301A	N3301A-908	5062-3960	53	–	–	–	1CM001A	–	–	Rackmount flange kit 177.0 mm H (4U) - one flange, one half-module flange
N3381A	N3381A-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
N3381A	N3381A-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
N3381B	N3381B-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
N3381B	N3381B-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
N3382A	N3382A-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
N3382A	N3382A-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
N3382B	N3382B-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
N3382B	N3382B-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
N3383A	N3383A-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
N3383A	N3383A-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
N3383B	N3383B-1CM	5063-9216	53	–	1CM015A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges; Rail kit, standard
N3383B	N3383B-1CP	5063-9236	53	–	–	1CM043A (1); E3663AC (1)	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles; Rail kit, standard
N4010A	N4994B-002	5063-9241	2863	–	–	–	1CM019A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one quarter-module flange
N432A	N432A-908	5063-9240	53	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
N432A	N432A-909	5063-9212	53	–	1CM007A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link for side-by-side mount
N4413A	N4413A-1CP	N4419-60001	53	–	–	–	–	N4419-60001	–	Rackmount kit
N4414A	N4414A-1CP	N4419-60001	53	–	–	–	–	N4419-60001	–	Rackmount kit
N4415A	N4415A-1CP	N4419-60001	53	–	–	–	–	N4419-60001	–	Rackmount kit
N4416A	N4416A-1CP	N4419-60001	53	–	–	–	–	N4419-60001	–	Rackmount kit
N4417A	N4417A-1CP	N4419-60001	53	–	–	–	–	N4419-60001	–	Rackmount kit
N4418A	N4418A-1CP	N4419-60001	53	–	–	–	–	N4419-60001	–	Rackmount kit
N4419A	N4419A-1CP	N4419-60001	53	–	–	–	–	N4419-60001	–	Rackmount kit
N4421A	N4421A-1CP	5063-9221	45	–	–	–	–	1CP008A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles
				–	–	–	–	1CP108A	–	Rackmount flange and handle kit 132.6 mm H (3U) - two flanges and front handles Keysight color
N4906A	N4906A-AX4	86100-60030	53	–	1CM030A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
N4906A	N4906A-AXE	86100-60031	53	–	–	–	–	1CP018A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
N5105A	N5105A-1CP	5063-9223	53	–	–	–	–	1CP026A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
N5105A	N5105A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
N5106A	N5106A-1CP	5063-9223	53	–	–	–	–	1CP026A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
N5106A	N5106A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115 (1); W1312-40032 (4)	Rack slide kit non-tilting; Bottom foot hole plug
N5151M	N5151M-1CM	5063-9212	53	–	1CM010A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges, four hole plugs
N5151M	N5151M-1CN	5063-9226	53	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
N5151M	N5151M-1CP	5063-9219	53	–	–	–	–	1CP011A (1); W1312-40032 (4)	–	Rackmount kit - 88.1H (2U) with handles; Bottom foot hole plug
N5151M	N5151M-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115 (1); W1312-40032 (4)	Rack slide kit non-tilting; Bottom foot hole plug

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
N5161A	N5161A-1CM	5063-9212	53	–	1CM010A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges, four hole plugs
N5161A	N5161A-1CN	5063-9226	53	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
N5161A	N5161A-1CP	5063-9219	53	–	–	–	–	1CP004A	–	Rackmount flange and handle kit 88.1 mm H (2U) - flanges, handles, hole plugs
N5161A	N5161A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115 (1); W1312-40032 (4)	Rack slide kit non-tilting; Bottom foot hole plug
N5162A	N5162A-1CM	5063-9212	53	–	1CM010A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges, four hole plugs
N5162A	N5162A-1CN	5063-9226	53	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
N5162A	N5162A-1CP	5063-9219	53	–	–	–	–	1CP004A	–	Rackmount flange and handle kit 88.1 mm H (2U) - flanges, handles, hole plugs
N5162A	N5162A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115 (1); W1312-40032 (4)	Rack slide kit non-tilting; Bottom foot hole plug
N5171B	–	–	53	1CN006A	1CM010A	–	–	1CP004A	1CR012A	Common accessories structured directly to Instrument, see corresponding category title
N5172B	–	–	53	1CN006A	1CM010A	–	–	1CP004A	–	Common accessories structured directly to Instrument, see corresponding category title
N5181A	N5181A-1CM	5063-9212	53	–	1CM010A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges, four hole plugs
N5181A	N5181A-1CN	5063-9226	53	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
N5181A	N5181A-1CP	5063-9219	53	–	–	–	–	1CP004A	–	Rackmount flange and handle kit 88.1 mm H (2U) - flanges, handles, hole plugs
N5181A	N5181A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115 (1); W1312-40032 (4)	Rack slide kit non-tilting; Bottom foot hole plug
N5181B	–	–	53	1CN006A	1CM010A	–	–	1CP004A	1CR012A	Common accessories structured directly to Instrument, see corresponding category title
N5182A	N5182A-1CM	5063-9212	53	–	1CM010A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges, four hole plugs

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
N5182A	N5182A-1CN	5063-9226	53	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
N5182A	N5182A-1CP	5063-9219	53	–	–	–	–	1CP004A	–	Rackmount flange and handle kit 88.1 mm H (2U) - flanges, handles, hole plugs
N5182A	N5182A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115 (1); W1312-40032 (4)	Rack slide kit non-tilting; Bottom foot hole plug
N5182B	–	–	53	1CN006A	1CM010A	–	–	1CP004A	–	Common accessories structured directly to Instrument, see corresponding category title
N5183A	N5183A-1CM	5063-9212	53	–	1CM010A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges, four hole plugs
N5183A	N5183A-1CN	5063-9226	53	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
N5183A	N5183A-1CP	5063-9219	53	–	–	–	–	1CP004A	–	Rackmount flange and handle kit 88.1 mm H (2U) - flanges, handles, hole plugs
N5183A	N5183A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115 (1); W1312-40032 (4)	Rack slide kit non-tilting; Bottom foot hole plug
N5183MU	N5183MU-857	5063-9226	53	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
N5221A	N5221A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5221A	N5221A-1CP	5063-9237	53	–	–	–	–	5063-9237 (1); 1CN020A (1); E3663AC (1)	–	Rackmount flange kit; Handle kit 265.9 mm H (6U) - two front handles; Rail kit, standard
N5222A	N5222A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5222A	N5222A-1CP	5063-9237	53	–	–	–	–	5063-9237 (1); 1CN020A (1); E3663AC (1)	–	Rackmount flange kit; Handle kit 265.9 mm H (6U) - two front handles; Rail kit, standard
N5224A	N5224A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5224A	N5224A-1CP	5063-9237	53	–	–	–	–	5063-9237 (1); 1CN020A (1); E3663AC (1)	–	Rackmount flange kit; Handle kit 265.9 mm H (6U) - two front handles; Rail kit, standard
N5225A	N5225A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
N5225A	N5225A-1CP	5063-9237	53	–	–	–	–	5063-9237 (1); 1CN020A (1); E3663AC (1)	–	Rackmount flange kit; Handle kit 265.9 mm H (6U) - two front handles Rail kit, standard
N5227A	N5227A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5227A	N5227A-1CP	5063-9237	53	–	–	–	–	5063-9237 (1); 1CN020A (1); E3663AC (1)	–	Rackmount flange kit; Handle kit 265.9 mm H (6U) - two front handles Rail kit, standard
N5230A	N5230A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5230A	N5230A-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
N5230C	N5230C-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5230C	N5230C-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
N5231A	N5231A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5231A	N5231A-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
N5232A	N5232A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5232A	N5232A-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
N5241A	N5241A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5241A	N5241A-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
N5242A	N5242A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5242A	N5242A-1CP	5063-9237	53	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
N5244A	N5244A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5244A	N5244A-1CP	5063-9237	53	–	–	–	–	5063-9237 (1); 1CN020A (1); E3663AC (1)	–	Rackmount flange kit; Handle kit 265.9 mm H (6U) - two front handles; Rail kit, standard
N5245A	N5245A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
N5245A	N5245A-1CP	5063-9237	53	–	–	–	–	5063-9237 (1); 1CN020A (1); E3663AC (1)	–	Rackmount flange kit; Handle kit 265.9 mm H (6U) - two front handles; Rail kit, standard
N5247A	N5247A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5247A	N5247A-1CP	5063-9237	53	–	–	–	–	5063-9237 (1); 1CN020A (1); E3663AC (1)	–	Rackmount flange kit; Handle kit 265.9 mm H (6U) - two front handles; Rail kit, standard
N5249A	N5249A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5249A	N5249A-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5249A	N5249A-1CP	5063-9230	53	5063-9230	–	–	–	–	–	Handle kit 265.9 mm H (6U) - two front handles
N5249A	N5249A-1CP	5063-9237	53	–	–	–	–	–	–	Rackmount kit; Handle kit 265.9 mm H (6U) - two front handles; Rail kit, standard
N5249A	N5249A-1CP	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5262A	N5262A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N5262A	N5262A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N5262A	N5262A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N5264A	N5264A-1CM	5063-9217	21	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N5264A	N5264A-1CP	5063-9237	21	–	–	5063-9237 (1); E3663AC (1)	–	–	–	Rackmount flange kit - two flanges; Rail kit, standard
N6700A	N6700A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6700B	N6700B-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6701A	N6701A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6702A	N6702A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6705A	N6705A-908	5063-9215	21	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N6705A	N6705A-909	5063-9222	21	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
N6705B	N6705B-908	5063-9215	21	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N6705B	N6705B-909	5063-9222	21	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N6710A	N6710A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6710B	N6710B-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6711A	N6711A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6712A	N6712A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6715A	N6715A-908	5063-9215	21	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N6715A	N6715A-909	5063-9222	21	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N6721A	N6721A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6722A	N6722A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6723A	N6723A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6724A	N6724A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6725A	N6725A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6726A	N6726A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6727A	N6727A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6728A	N6728A-908	N6700-60009	21	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N6729A	N6729A-908	N6700-60009	53	–	N6709A	–	–	–	–	Rackmount flange kit 44.5 mm H (1U)
N8300A	N8300A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N8300A	N8300A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N8300A	N8300A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N8300A	N8300A-1CR	1494-0060	53	–	–	–	–	–	1494-0060	Kit-Slide, Standard
N8972A	N8972A-1CP	N8972-61014	53	–	–	–	–	N8972-61014	–	Rackmount and handle slide kit 221.5 mm H (5U) - panel adapter support flange
N8973A	N8973A-1CP	N8972-61014	53	–	–	–	–	N8972-61014	–	Rackmount and handle slide kit 221.5 mm H (5U) - panel adapter support flange

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
N8974A	N8974A-1CP	N8972-61014	53	–	–	–	–	N8972-61014	–	Rackmount and handle slide kit 221.5 mm H (5U) - panel adapter support flange
N8975A	N8975A-1CP	N8972-61014	C8	–	–	–	–	N8972-61014	–	Rackmount and handle slide kit 221.5 mm H (5U) - panel adapter support flange
N9000A	N9000A-1CM	5063-9215	C8	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9000A	N9000A-1CN	5063-9228	C8	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9000A	N9000A-1CP	5063-9222	C8	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9000A	N9000A-1CR	E4406-60115	C8	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
N9000AK	N9000AK-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9000AK	N9000AK-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9000AK	N9000AK-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9000AK	N9000AK-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
N9010A	N9010A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9010A	N9010A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9010A	N9010A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9010A	N9010A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
N9010AK	N9010AK-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9010AK	N9010AK-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9010AK	N9010AK-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9010AK	N9010AK-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
N9020A	N9020A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9020A	N9020A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9020A	N9020A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9020A	N9020A-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
N9020AK	N9020AK-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9020AK	N9020AK-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9020AK	N9020AK-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9020AK	N9020AK-1CR	E4406-60115	53	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
N9030A	N9030A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9030A	N9030A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9030A	N9030A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9030A	N9030A-1CR	N9030-60007	53	–	–	–	–	–	N9030-60007	Rack slide
N9030AK	N9030AK-1CM	5063-9215	2863	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9030AK	N9030AK-1CN	5063-9228	2863	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9030AK	N9030AK-1CP	5063-9222	2863	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9030AK	N9030AK-1CR	N9030-60007	2863	–	–	–	–	–	N9030-60007	Rack Slide
N9038A	N9038A-1CM	5063-9215	2863	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9038A	N9038A-1CN	5063-9228	2863	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9038A	N9038A-1CP	5063-9222	2863	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
N9038AK	N9038AK-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9038AK	N9038AK-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9038AK	N9038AK-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9039A	N9039A-1CM	5063-9215	2863	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9039A	N9039A-1CN	5063-9228	2863	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9039A	N9039A-1CP	5063-9222	2863	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9039A	N9039A-1CR	E4406-60115	2863	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
N9039AK	N9039AK-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9039AK	N9039AK-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9039AK01	N9039AK01-1CM	5063-9215	C8	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N9039AK01	N9039AK01-1CN	5063-9228	C8	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
N9039AK01	N9039AK01-1CP	5063-9222	C8	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N9039AK01	N9039AK01-1CR	E4406-60115	C8	–	–	–	–	–	E4406-60115	Rack slide kit non-tilting
N9040B	N9040B-1CM	5063-9217	53	–	1CM042A (1); E3663AC (1)	–	–	–	–	Rackmount flange kit 265.9 mm H (6U) - two flanges; Rail kit, standard
N9040B	N9040B-1CP	5063-9237	53	–	–	–	–	5063-9237 (1); 1CN020A (1); E3663AC (1)	–	Rackmount kit; Handle kit 265.9 mm H (6U) - two front handles; Rail kit, standard
N9310A	N9310A-1CM	N9310-80001	C8	–	–	–	–	Contact parts ID	–	Contact parts ID
N9310AK	N9310AK-1CM	N9310-80001	C8	–	–	–	–	Contact parts ID	–	Contact parts ID
N9320A	N9320A-1CM	N9310-80001	C8	–	–	–	–	Contact parts ID	–	Contact parts ID
N9320AK	N9320AK-1CM	N9310-80001	C8	–	–	–	–	Contact parts ID	–	Contact parts ID
N9320B	N9320B-1CM	N9310-80001	C8	–	–	–	–	N9310-80001	–	Rackmount flange and handle kit

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
N9320B	N9320B-1CP	N9320-60014	2863	–	N9320-60014	–	–	–	–	Rackmount kit without handle
N9320BK	N9320BK-1CM	N9310-80001	2863	–	–	–	–	N9310-80001	–	Rackmount flange and handle kit
N9320BK	N9320BK-1CP	N9320-60014	2863	–	N9320-60014	–	–	–	–	Rackmount kit without handle
U2972A	U2972A-1CM	5063-9240	53	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
U3020AS22	U3020AS22-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3020AS22	U3020AS22-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3020AS22	U3020AS22-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3022AE06	U3022AE06-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3022AE06	U3022AE06-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3022AE06	U3022AE06-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3022AE10	U3022AE10-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3022AE10	U3022AE10-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3022AE10	U3022AE10-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3022AH10	U3022AH10-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3022AH10	U3022AH10-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3022AH10	U3022AH10-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 117.0 mm H (4U) - two flanges and front handles
U3022AM06	U3022A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3022AM06	U3022A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
U3022AM06	U3022A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3022AM14	U3022A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3022AM14	U3022A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3022AM14	U3022A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3022AS22	U3022AS22-1CM	5063-9215	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3022AS22	U3022AS22-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3022AS22	U3022AS22-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3022AS66	U3022AS66-1CM	5063-9212	53	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
U3022AS66	U3022AS66-1CN	5063-9226	53	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
U3022AS66	U3022AS66-1CP	5063-9232	53	–	–	5063-9232	–	–	–	Rackmount kit with handles 88.1 mm H (2U) - two flanges and handles
U3022UM06	U3042A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3022UM06	U3042A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3022UM06	U3042A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3024AE06	U3024AE06-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3024AE06	U3024AE06-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3024AE06	U3024AE06-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
U3025AE06	U3025AE06-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3025AE06	U3025AE06-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3025AE06	U3025AE06-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3025AE10	U3025AE10-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3025AE10	U3025AE10-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3025AE10	U3025AE10-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3025AS06	U3025AS06-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3025AS06	U3025AS06-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3025AS06	U3025AS06-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3026AE10	U3026AE10-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3026AE10	U3026AE10-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3026AE10	U3026AE10-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3035P	U3035P-1CM	5063-9212	53	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
U3035P	U3035P-1CN	5063-9226	53	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
U3035P	U3035P-1CP	5063-9232	53	–	–	5063-9232	–	–	–	Rackmount kit with handles 88.1 mm H (2U) - two flanges and handles
U3035P	U3035P-2CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3035P	U3035P-2CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
U3035P	U3035P-2CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3042A	U3042A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3042A	U3042A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3042A	U3042A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3042AE04	U3042A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3042AE04	U3042A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3042AE04	U3042A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3042AE08	U3042AE08-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3042AE08	U3042AE08-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3042AE08	U3042AE08-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3042AE12	U3042AE12-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3042AE12	U3042AE12-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3042AE12	U3042AE12-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3042AE16	U3042AE16-1CM	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
U3042AE16	U3042AE16-1CN	5063-9229	53	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
U3042AE16	U3042AE16-1CP	5063-9236	53	–	–	1CM043A	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges for units with existing handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
U3042AM04	U3042A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3042AM04	U3042A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3042AM04	U3042A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3042AM08	U3042A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3042AM08	U3042A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3042AM08	U3042A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3042AM12	U3042A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3042AM12	U3042A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3042AM12	U3042A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3042AM12	U3042AM12-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3042AM12	U3042AM12-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3042AM12	U3042AM12-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3042AM20	U3042A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3042AM20	U3042A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3042AM20	U3042A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3042AM20	U3042AM20-1CM	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
U3042AM20	U3042AM20-1CN	5063-9229	53	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
U3042AM20	U3042AM20-1CP	5063-9223	53	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
U3044AM12	U3044A-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3044AM12	U3044A-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3044AM12	U3044A-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3045AM04	U3045AM04-1CM	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
U3045AM04	U3045AM04-1CN	5063-9229	53	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
U3045AM04	U3045AM04-1CP	5063-9223	53	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
U3045AM12	U3045AM12-1CM	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
U3045AM12	U3045AM12-1CN	5063-9229	53	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
U3045AM12	U3045AM12-1CP	5063-9223	53	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles
U3047AE04	U3047AE04-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
U3047AE04	U3047AE04-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
U3047AE04	U3047AE04-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
U3047AM04	U3047AM04-1CM	5063-9216	53	–	1CM015A	–	–	–	–	Rackmount flange kit 221.5 mm H (5U) - two flanges
U3047AM04	U3047AM04-1CN	5063-9229	53	1CN005A	–	–	–	–	–	Handle kit 221.5 mm H (5U) - two front handles
U3047AM04	U3047AM04-1CP	5063-9223	53	–	–	–	–	1CP020A	–	Rackmount flange and handle kit 221.5 mm H (5U) - two flanges and front handles

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
U3050AH11	U3050AH11-1CM	5063-9212	2863	–	34191A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges
U3050AH11	U3050AH11-1CN	5063-9226	2863	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
U3050AH11	U3050AH11-1CP	5062-3975	2863	–	–	–	–	1CP014A	–	Double Rackmount flange and handle kit 88.1 mm H (2U) and 132.6 mm H (3U) - four flanges and handles (5U total)
U3401A	U3400A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
U3402A	U3400A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
U3606A	U3606A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
U3606A	U3606A-1CN	5063-9212	2863	–	1CM011A	–	–	–	–	Rackmount flange kit without handles 88.1 mm H (2U) - two flanges, lock link kit
U8001A	U8001A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
U8002A	U8002A-1CM	5063-9240	2863	–	–	–	34190A	–	–	Rackmount adapter kit 88.1 mm H (2U) - one flange and one half-module flange
U8031A	U8031A-1CM	5063-9245	2863	–	–	–	1CM068A	–	–	Rackmount flange kit 177.0 mm H (4U) - one flange, one half-module flange
U8032A	U8032A-1CM	5063-9245	2863	–	–	–	1CM068A	–	–	Rackmount flange kit 177.0 mm H (4U) - one flange, one half-module flange
U8903A	U8903A-908	5063-9214	2863	–	34192A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges
U9101A	U9101A-908	5063-9214	53	–	Contact parts ID	–	–	–	–	Contact parts ID
V2802A	V2802A-1CM	5063-9212	53	–	1CM010A	–	–	–	–	Rackmount flange kit 88.1 mm H (2U) - two flanges, four hole plugs
V2802A	V2802A-1CN	5063-9226	53	1CN006A	–	–	–	–	–	Handle kit 88.1 mm H (2U) - two front handles
V2802A	V2802A-1CP	5063-9232	53	–	–	5063-9232	–	–	–	Rackmount kit with handles 88.1 mm H (2U) - two flanges and handles
V2820A	V2820A-1CM	2890-RK-KIT-1A	53	–	–	–	Contact parts ID	–	–	Contact parts ID

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
V2920A	V2920A-1CM	2890-RK-KIT-1A	53	–	–	–	Contact parts ID	–	–	Contact parts ID
V2999A	V2999A-1CM	2890-RK-KIT-1A	53	–	–	–	Contact parts ID	–	–	Contact parts ID
Z5623AK44	Z5623AK44-1CM	5063-9215	53	–	1CM013A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges
N8973B	–	1CM113A	53	–	1CM113A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges - Keysight color
N8974B	–	1CM113A	53	–	1CM113A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges - Keysight color
N8975B	–	1CM113A	53	–	1CM113A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges - Keysight color
N8976B	–	1CM113A	53	–	1CM113A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges - Keysight color
N9000B	–	1CM113A	C8	–	1CM113A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges - Keysight color
N9010B	–	1CM113A	53	–	1CM113A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges - Keysight color
N9020B	–	1CM113A	53	–	1CM113A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges - Keysight color
N9030B	–	1CM113A	53	–	1CM113A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges - Keysight color
V2802A	–	1CM113A	53	–	1CM113A	–	–	–	–	Rackmount flange kit 177.0 mm H (4U) - two flanges - Keysight color
N8973B	–	1CN103A	53	1CN103A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles - Keysight color
N8974B	–	1CN103A	53	1CN103A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles - Keysight color
N8975B	–	1CN103A	53	1CN103A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles - Keysight color
N8976B	–	1CN103A	53	1CN103A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles - Keysight color
N9000B	–	1CN103A	C8	1CN103A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles - Keysight color
N9010B	–	1CN103A	53	1CN103A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles - Keysight color
N9020B	–	1CN103A	53	1CN103A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles - Keysight color
N9030B	–	1CN103A	53	1CN103A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles - Keysight color

Technical Specifications (Continued)

Instrument information				Common accessory product categories						Description
Instrument	Instrument option	Primary component	Option er_code	Handles	Rackmount	Rackmount for units with existing handles	Rackmount adapter kit with filler panel	Rackmount including handles	Rack slide	Accessory product description
V2802A	–	1CN103A	53	1CN103A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles - Keysight color
Z5623AK44	Z5623AK44-1CN	5063-9228	53	1CN003A	–	–	–	–	–	Handle kit 177.0 mm H (4U) - two front handles
Z5623AK44	Z5623AK44-1CP	5063-9222	53	–	–	–	–	1CP005A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles
N8973B	–	1CP105A	53	–	–	–	–	1CP105A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles - Keysight color
N8974B	–	1CP105A	53	–	–	–	–	1CP105A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles - Keysight color
N8975B	–	1CP105A	53	–	–	–	–	1CP105A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles - Keysight color
N8976B	–	1CP105A	53	–	–	–	–	1CP105A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles - Keysight color
N9000B	–	1CP105A	C8	–	–	–	–	1CP105A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles - Keysight color
N9010B	–	1CP105A	53	–	–	–	–	1CP105A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles - Keysight color
N9020B	–	1CP105A	53	–	–	–	–	1CP105A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles - Keysight color
N9030B	–	1CP105A	53	–	–	–	–	1CP105A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles - Keysight color
V2802A	–	1CP105A	53	–	–	–	–	1CP105A	–	Rackmount flange and handle kit 177.0 mm H (4U) - two flanges and front handles - Keysight color
N5193A	–	1CM104A	53	–	1CM104A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges - Palette 2015
N5191A	–	1CM104A	53	–	1CM104A	–	–	–	–	Rackmount flange kit 132.6 mm H (3U) - two flanges - Palette 2015

myKeysight

myKeysight
www.keysight.com/find/mykeysight
 A personalized view into the information most relevant to you.

KEYSIGHT SERVICES
 Accelerate Technology Adoption.
 Lower costs.

Keysight Services
www.keysight.com/find/service
 Our deep offering in design, test, and measurement services deploys an industry-leading array of people, processes, and tools. The result? We help you implement new technologies and engineer improved processes that lower costs.



Three-Year Warranty
www.keysight.com/find/ThreeYearWarranty
 Keysight's committed to superior product quality and lower total cost of ownership. Keysight is the only test and measurement company with three-year warranty standard on all instruments, worldwide. And, we provide a one-year warranty on many accessories, calibration devices, systems and custom products.



Keysight Assurance Plans
www.keysight.com/find/AssurancePlans
 Up to ten years of protection and no budgetary surprises to ensure your instruments are operating to specification, so you can rely on accurate measurements.




www.keysight.com/go/quality
 Keysight Technologies, Inc.
 DEKRA Certified ISO 9001:2015
 Quality Management System

Keysight Channel Partners
www.keysight.com/find/channelpartners
 Get the best of both worlds: Keysight's measurement expertise and product breadth, combined with channel partner convenience.

Evolving

Our unique combination of hardware, software, support, and people can help you reach your next breakthrough. **We are unlocking the future of technology.**

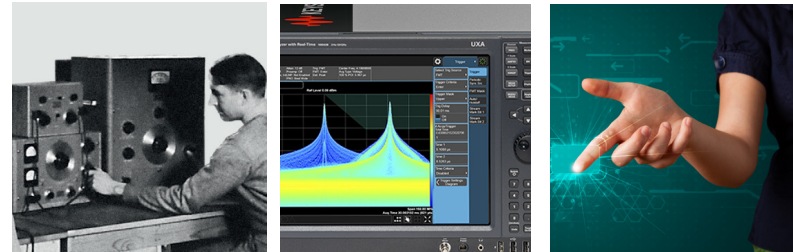

From Hewlett-Packard to Agilent to Keysight



For more information on Keysight Technologies' products, applications or services, please contact your local Keysight office. The complete list is available at: www.keysight.com/find/contactus

Americas

Canada	(877) 894 4414
Brazil	55 11 3351 7010
Mexico	001 800 254 2440
United States	(800) 829 4444

Asia Pacific

Australia	1 800 629 485
China	800 810 0189
Hong Kong	800 938 693
India	1 800 11 2626
Japan	0120 (421) 345
Korea	080 769 0800
Malaysia	1 800 888 848
Singapore	1 800 375 8100
Taiwan	0800 047 866
Other AP Countries	(65) 6375 8100

Europe & Middle East

Austria	0800 001122
Belgium	0800 58580
Finland	0800 523252
France	0805 980333
Germany	0800 6270999
Ireland	1800 832700
Israel	1 809 343051
Italy	800 599100
Luxembourg	+32 800 58580
Netherlands	0800 0233200
Russia	8800 5009286
Spain	800 000154
Sweden	0200 882255
Switzerland	0800 805353
	Opt. 1 (DE)
	Opt. 2 (FR)
	Opt. 3 (IT)
United Kingdom	0800 0260637

For other unlisted countries:
www.keysight.com/find/contactus
 (BP-09-23-16)