


# Product data sheet

## Characteristics

# 9001SKR9P35LRRH13

Harmony 9001SK, illuminated push-button, plastic, mushroom 41mm, red, 30mm, 2 positions, push-pull, LED red, 24-28V, 1 C/O

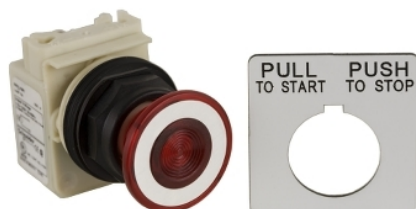

### Main

|                                 |                         |
|---------------------------------|-------------------------|
| Range of Product                | Harmony 9001SK          |
| Product or Component Type       | Illuminated push-button |
| Device short name               | 9001SK                  |
| Operator additional information | Screw-on plastic        |

### Complementary

|                               |                  |
|-------------------------------|------------------|
| Bezel material                | Plastic          |
| Mounting diameter             | 1.18 in (30 mm)  |
| Contacts type and composition | 1 C/O            |
| Contact operation             | Standard         |
| Mechanical durability         | 5000000 cycles   |
| Device presentation           | Complete product |

### Environment

|                           |  |
|---------------------------|--|
| Standards                 | EN/IEC 60947-5-1<br>EN/IEC 60947-1<br>JIS C 4520<br>CSA C22.2 No 14<br>EN/IEC 60947-5-4<br>JIS C 852<br>UL 508 |
| IP degree of protection   | IP66   |
| NEMA degree of protection | NEMA 1/2/3/3R/4/4X/6/12/13   |

### Ordering and shipping details

|                       |                        |
|-----------------------|------------------------|
| Category              | 21429-9001 SK,SKY      |
| Discount Schedule     | CS1                    |
| GTIN                  | 785901043133           |
| Nbr. of units in pkg. | 1                      |
| Package weight(Lbs)   | 3.65 lb(US) (1.656 kg) |
| Returnability         | No                     |
| Country of origin     | MX                     |

### Packing Units

|                        |                    |
|------------------------|--------------------|
| Unit Type of Package 1 | PCE                |
| Package 1 Height       | 2.50 in (6.35 cm)  |
| Package 1 width        | 2.00 in (5.08 cm)  |
| Package 1 Length       | 4.50 in (11.43 cm) |

## Offer Sustainability

|                            |   |
|----------------------------|---|
| Sustainable offer status   | Green Premium product   |
| California proposition 65  | WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a> |
| REACH Regulation           | <a href="#">REACH Declaration</a>   |
| REACH free of SVHC         | Yes   |
| EU RoHS Directive          | Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>  |
| Toxic heavy metal free     | Yes   |
| Mercury free               | Yes   |
| RoHS exemption information | <a href="#">Yes</a>   |
| China RoHS Regulation      | <a href="#">China RoHS Declaration</a>  |
| Environmental Disclosure   | <a href="#">Product Environmental Profile</a>   |
| WEEE                       | The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.  |

## Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|