

Features

- Thermocouple Type R/S.
- Rated to +425°C.
- Standard Size Thermocouple Socket.
- Heavy duty plastic body.

High Temperature (+425°C) Standard Thermocouple Connector Socket Type R/S

RS Stock No.: 2816792



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description


Thermocouple Connector Socket



High temperature for use up to 425°C. Heavy duty plastic body.

General Specifications

General Description	Contacts are polarised to prevent incorrect connection. Heavy duty plastic body
Thermocouple Type	R/S
Connector Type	High Temp Socket
Connector Size	Standard
Colour	Brown
Dimensions	L x W x H – 33.3 x 25.4 x 12.7
Max. Temperature	425°C
+Positive Contact	Copper
-Negative Contact	Copper Alloy
Standards Met	BS EN 50212:1997. RoHS

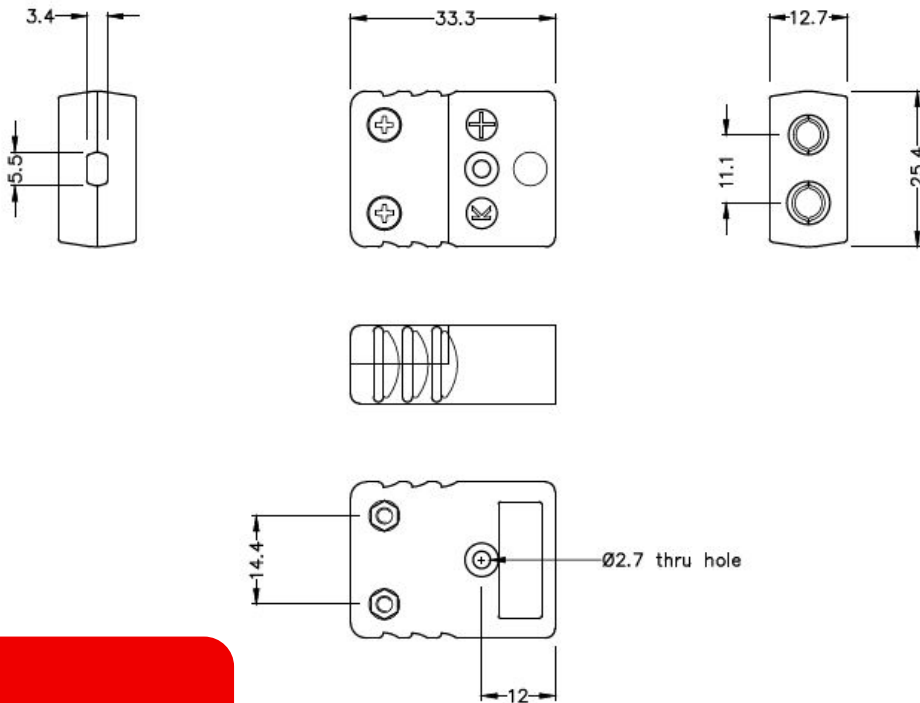

Approvals

RoHS Compliant	Yes
-----------------------	-----

Ordering Information

Stock No.	Type	Colour	Size
2816792	R/S	Brown	Standard socket