




 PRODUCT-DETAILS

DRS-F-03

DRS-F-03 Remote Reset Coil

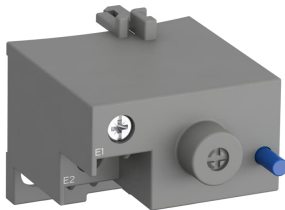

General Information

| | |
|-----------------------|--|
| Extended Product Type | DRS-F-03 |
| Product ID | 1SAX101911R1003 |
| EAN | 4013614488429 |
| Catalog Description | DRS-F-03 Remote Reset Coil |
| Long Description | The DRS-F-03 remote reset coil is used to remotely reset the thermal overload relays TF42, TF65 and TF96 as well as the electrical overload relays EF19 to EF1250. To enable remote resetting, the overload relay needs to be in "manual" reset mode. The coil is not approved for continuous operation. Pulse duration 0.2... 0.35 s. |

Ordering

| | |
|------------------------|----------|
| Minimum Order Quantity | 1 piece |
| Customs Tariff Number | 85365080 |

Popular Downloads

| | |
|-----------------------------------|-----------------|
| Data Sheet, Technical Information | 1SBC100214C0202 |
| Instructions and Manuals | 2CDC106081M6802 |

| | |
|--------------------------------------|-----------------|
| Instructions and Manuals (Part 2) | 1SAC200017M0002 |
| CAD Dimensional Drawing | 2CDC001079B0201 |

Dimensions

| | |
|-------------------------------|----------|
| Product Net Width | 44 mm |
| Product Net Height | 43 mm |
| Product Net Depth / Length | 60 mm |
| Product Net Weight | 0.077 kg |

Technical

| | |
|--------------|---|
| Suitable For | TF42 TF65 TF96 EF19 EF45 EF65 EF96 EF146 EF205 EF370 EF460 EF750 EF1250 |
|--------------|---|

Material Compliance

| | |
|---|--|
| Conflict Minerals Reporting Template (CMRT) | 9AKK108467A5658 |
| REACH Declaration | 2CMT2021-006202 |
| RoHS Information | 2CMT2021-006277 |
| RoHS Status | Following EU Directive 2011/65/EU and Amendment 2015/863 July 22, 2019 |
| Toxic Substances Control Act - TSCA | 2CMT2023-006525 |
| WEEE B2C / B2B | Business To Business |
| WEEE Category | 5. Small Equipment (No External Dimension More Than 50 cm) |

Certificates and Declarations

| | |
|-------------------------------------|-----------------|
| Declaration of Conformity - CE | 1SAD101100-3504 |
| Declaration of Conformity - UKCA | 1SAD201100-3504 |
| UL Certificate | E48139-20130329 |

Container Information

| | |
|-----------------------------------|---------------|
| Package Level 1 Units | 1 piece |
| Package Level 1 Width | 65 mm |
| Package Level 1 Height | 51 mm |
| Package Level 1 Depth / Length | 49 mm |
| Package Level 1 Gross Weight | 0.096 kg |
| Package Level 1 EAN | 4013614488429 |
| Package Level 2 Units | 150 piece |

| | |
|--------------------------------|----------|
| Package Level 2 Width | 350 mm |
| Package Level 2 Height | 330 mm |
| Package Level 2 Depth / Length | 255 mm |
| Package Level 2 Gross Weight | 14.95 kg |

Classifications

| | |
|------------------------------------|--|
| ETIM 5 | EC002498 - Accessories for low-voltage switch technology |
| ETIM 6 | EC002498 - Accessories for low-voltage switch technology |
| ETIM 7 | EC002498 - Accessories for low-voltage switch technology |
| ETIM 8 | EC002498 - Accessories/spare parts for low-voltage switch technology |
| eClass | V11.0 : 27371392 |
| UNSPSC | 39122221 |
| IDEA Granular Category Code (IGCC) | 5219 >> Switch part or accessory |

Categories

Low Voltage Products and Systems → Control Products → Contactors → Thermal Overload Relays

