

Illuminated pushbutton Ø 22 mm silver contact

82-6151.1114.B002



<https://eao.com/p/82-6151.1114.B002>

Your product:



82-6151.1114.B002
Illuminated pushbutton Ø
22 mm silver contact

FRONT

Front bezel material: Stainless steel

MOUNTING

Mounting cut-out: Ø 22 mm

OPERATING-/INDICATION PART

Lens illumination: illuminative

Shape of illumination: Ring

Lens colour: Silver

Lens material: Stainless steel

Illumination colour: Red

Lens optics: opaque

Lens shape: flush

ELECTRICAL CHARACTERISTICS

Pollution degree: 2, according to EN IEC 60947-1

Thermal current I_{th}: 5 A

Operating voltage: 24 V AC/DC

Switching voltage and switching current:

according to IEC 60947-5-1 (Silver contacts)

Service categorie AC-15

Voltage

24 VAC

35 VAC

110 VAC

220 VAC

Current

1 A

1 A (M12 version)

1 A

0.5 A

Switch rating DC service categorie DC-13 (Silver contacts)

Voltage

24 VDC

35 VDC

110 VDC

220 VDC

Current

0.7 A

0.5 A (M12 version)

0.2 A

0.1 A

according to UL 508 (Silver contacts)

$\cos\phi$ 0,75 ... 0,8

Voltage

120 VAC

240 VAC

24 VAC

Current

5 A

3 A

1 A

Rated Operational Voltage U_e:	250 VAC
Electrical lifetime:	50 000 cycles of operation
Electric strength:	1500 VAC, 50 Hz 1 minute between life terminals and ground
Rated insulation voltage U_i:	250 V
Contacts:	1 C

MECHANICAL CHARACTERISTIC

Mechanical lifetime:	1 Mio. cycles of operation
Operating Travel:	ca. 3 mm
Operating force:	4 N ... 7 N
Switching action:	Momentary
Weight:	0.018 kg
Switching system:	Snap-action switching element
Tightening torque:	0.5 ... 0.6 Nm
Contact material:	Silver
Terminal:	Soldering terminal, 2.8 x 0.5 mm

AMBIENT CONDITION

Vibration resistance:	10 ... 500 Hz, amplitude 1.5 mm p-p according to IEC 60068-2-6
Operating temperature:	- 30 °C ... + 70 °C
Shock resistance:	Max. 500 m / s ² as per IEC 60068-2-27
Climate resistance:	

Damp heat, 21 days according to IEC 60512-11

Storage temperature: - 40 °C ... + 80 °C

CERTIFICATE

Conformities: CE, 2011 / 65 / EC (RoHS), 2014 / 35 / EU (LVD)

Approbations: CB, CCC, C UL, UL


OTHER

Short Description: Illuminated pushbutton Ø 22 mm silver contact, Momentary, 24 V AC/DC, 1 C, Soldering terminal, 2.8 x 0.5 mm, Stainless steel, Red, Standby, Silver


Kind of illumination: Single-LED

Symbol: Standby


Wiring diagrams:

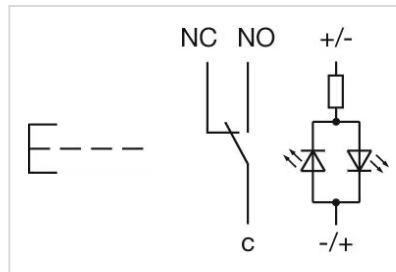

Dimension drawings:

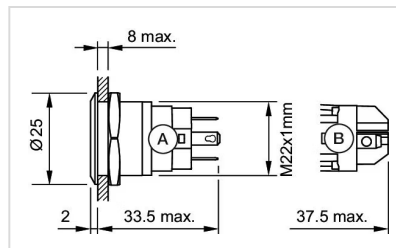

Component layouts:

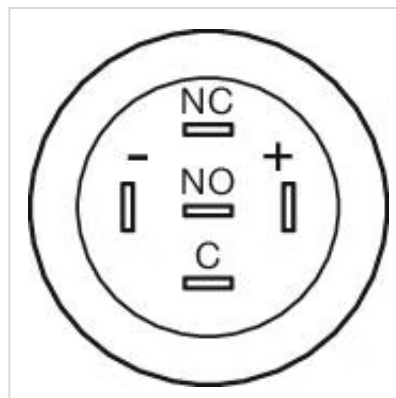

Mounting cut-outs:

