

Actuator

45-
290K.1000.116



<https://eao.com/p/45-290K.1000.116>

Your product:



45-290K.1000.116 Actuator

FRONT

| | |
|------------------------------|-----------|
| Front dimension: | Ø 29,5 mm |
| Front bezel colour: | Black |
| Front bezel material: | Plastic |

MOUNTING

| | |
|----------------|--------|
| Design: | raised |
|----------------|--------|

MECHANICAL CHARACTERISTIC

| | |
|-----------------------------|----------------------------|
| Weight: | 0.054 kg |
| Switching action: | Rest (a) - Momentary |
| Switching positions: | 2 positions |
| Switching angle: | 45° right |
| Mechanical lifetime: | 1 Mio. cycles of operation |
| Operating frequency: | 1 800/h |

AMBIENT CONDITION

| | |
|-------------------------------|--|
| IP front protection: | IP66, IP67, IP69K |
| Operating temperature: | - 25 °C ... + 70 °C |
| Storage temperature: | - 40 °C ... + 80 °C |
| Climate resistance: | During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6 |
| Vibration resistance: | According to IEC 60068-2-6: 10 ... 500 Hz: 5 g |
| Shock resistance: | According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms |

OTHER

Housing material:

Plastic


Hints:

The standard lock: RONIS, T254

Short Description:

Actuator, Ø 29,5 mm, Black, Plastic, Rest (a) - Momentary, IP66, IP67, IP69K


Switching positions:

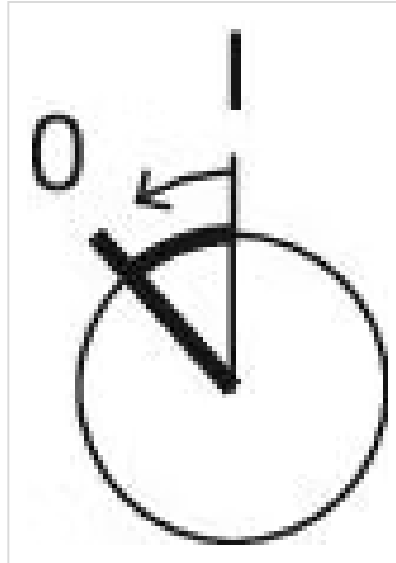

Wiring diagrams:



Mounting cut-outs:

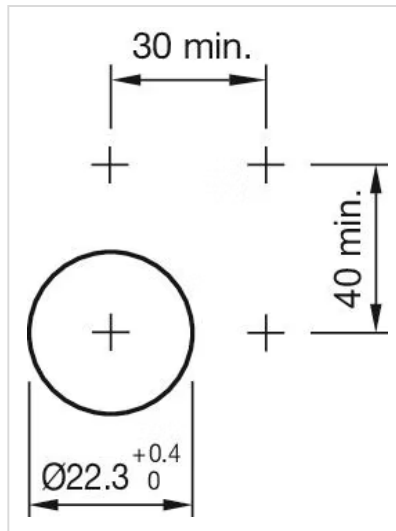

Dimension drawings:

