

Illuminated pushbutton Ø 19 mm silver contact

82-5151.2124



<https://eao.com/p/82-5151.2124>

Your product:



82-5151.2124

Illuminated pushbutton Ø 19 mm silver contact

FRONT

Front bezel material: Stainless steel

MOUNTING

Mounting cut-out: Ø 19 mm

OPERATING-/INDICATION PART

Lens material: Stainless steel

Lens illumination: illuminative

Lens shape: flush

Lens optics: opaque

Shape of illumination: Ring

Illumination colour: Blue

Lens colour: Silver

ELECTRICAL CHARACTERISTICS

Thermal current I_{th}: 5 A

Rated insulation voltage U_i: 250 V

Rated Operational Voltage U_e: 250 VAC

Switching voltage and switching current:

according to IEC 60947-5-1 (Silver contacts)	
Service categorie AC-15	
Voltage	Current
24 VAC	1 A
35 VAC	1 A (M12 version)
110 VAC	1 A
220 VAC	0.5 A
Switch rating DC service categorie DC-13 (Silver contacts)	
Voltage	Current
24 VDC	0.7 A
35 VDC	0.5 A (M12 version)
110 VDC	0.2 A
220 VDC	0.1 A

according to UL 508 (Silver contacts)	
cosφ 0,75 ... 0,8	
Voltage	Current
120 VAC	5 A
240 VAC	3 A
24 VAC	1 A

Pollution degree:	2, according to EN IEC 60947-1
Operating voltage:	24 V DC
Electrical lifetime:	50 000 cycles of operation
Electric strength:	1500 VAC, 50 Hz 1 minute between life terminals and ground
Contacts:	1 C

MECHANICAL CHARACTERISTIC

Tightening torque:	0.5 ... 0.6 Nm
Weight:	0.018 kg
Operating Travel:	ca. 3 mm
Terminal:	Soldering terminal, 2.8 x 0.5 mm
Contact material:	Silver
Operating force:	4 N ... 7 N
Switching action:	Maintained
Switching system:	Snap-action switching element
Mechanical lifetime:	500 000 cycles of operation

AMBIENT CONDITION

Operating temperature:	- 30 °C ... + 70 °C
Shock resistance:	Max. 500 m / s ² as per IEC 60068-2-27
Vibration resistance:	10 ... 500 Hz, amplitude 1.5 mm p-p according to IEC 60068-2-6
Storage temperature:	

- 40 °C ... + 80 °C

Climate resistance: Damp heat, 21 days according to IEC 60512-11

CERTIFICATE

Conformities: CE, 2011 / 65 / EC (RoHS), 2014 / 35 / EU (LVD)


Approbations: CB, CCC, C UL, UL

OTHER


Kind of illumination: Single-LED

Short Description: Illuminated pushbutton Ø 19 mm silver contact, Maintained, 24 V DC, 1 C, Soldering terminal, 2.8 x 0.5 mm, Stainless steel, Blue, Silver


Wiring diagrams:

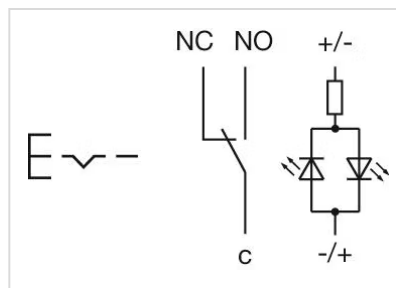

Component layouts:

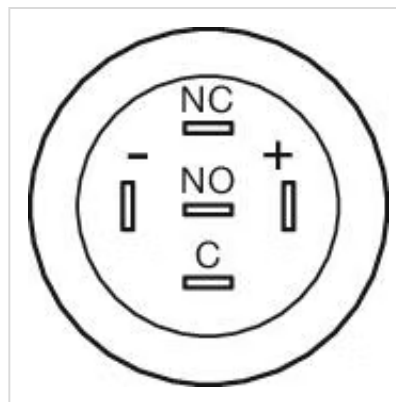

Dimension drawings:

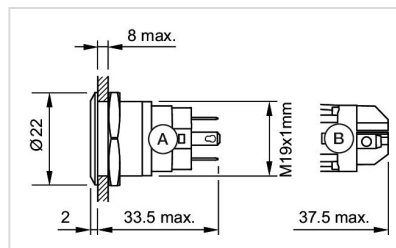

Mounting cut-outs:

