


# Actuator

704.064.2

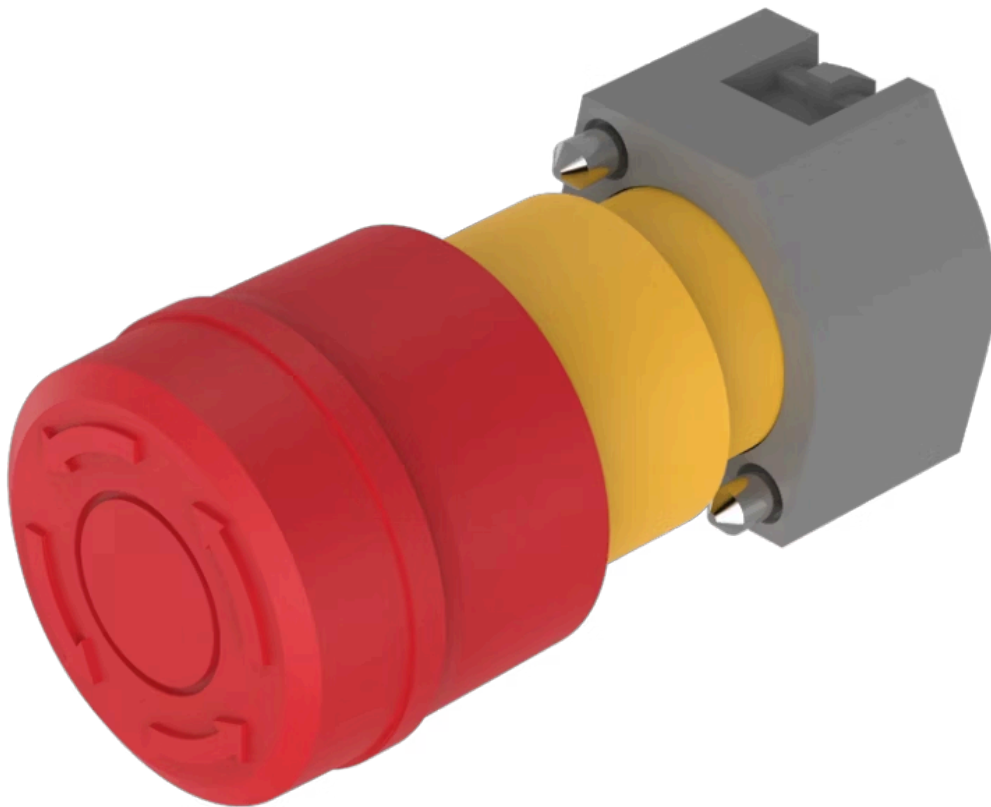

<https://eao.com/p/704.064.2>

Your product:

---



## 704.064.2 Actuator

### FRONT

**Front dimension:** Ø 37 mm

### MOUNTING

**Design:** raised

### OPERATING-/INDICATION PART

**Lens material:** Plastic

**Lens optics:** opaque

**Lens colour:** Red

**Lens illumination:** non illuminative

**Lens shape:** mushroom-head

### ELECTRICAL CHARACTERISTICS

**Standards:** The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1

### MECHANICAL CHARACTERISTIC

**Weight:** 0.055 kg

**Operating Travel:** ca. 5.8 mm ± 0.2 mm

**Mechanical lifetime:** ≤50 000 cycles of operation

**Switching action:** Maintained


**Operating force:** 8 N

## AMBIENT CONDITION


<b>Storage temperature:</b>	- 40 °C ... + 85 °C
<b>Operating temperature:</b>	- 40 °C ... + 55 °C
<b>IP Protection:</b>	IP65 front side

## OTHER

<b>Marking:</b>	Arrows
<b>Short Description:</b>	Actuator, Ø 37 mm, mushroom-head, non illuminative, Red, Plastic, opaque, Maintained
<b>Housing colour:</b>	Yellow
<b>Housing material:</b>	Plastic
<b>max. number of switching elements:</b>	2
<b>Hints:</b>	Shaft yellow
<b>Mounting cut-outs:</b>	

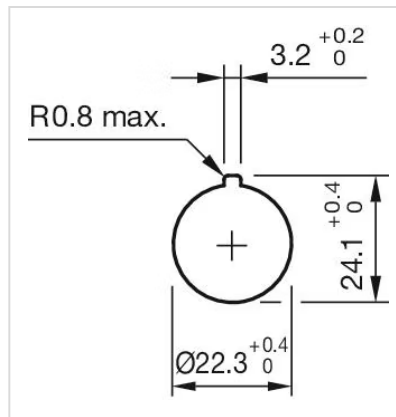

## Wiring diagrams:

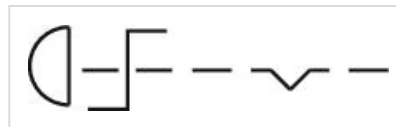

## Dimension drawings:

