

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16
- 17
- 18

MATERIAL

Polyethylene (PE), RAL 9005 (C9) black colour or RAL 7042 (C34) grey colour, satin finish.

STANDARD EXECUTIONS

- **NIL.Q:** for square tubes.
- **NIL.R:** for rectangular tubes.
- **NIL.T:** for round tubes.

FITTING


Their fitting to the round, square or rectangular section tube or profile ends can be made either by hand or by a mallet.

SPECIAL EXECUTIONS ON REQUEST

RAL 9003 white coloured inserts.



NIL.Q

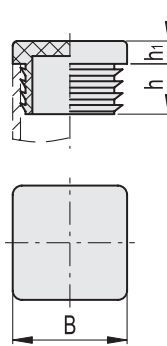

* Complete with colour index, example: 435210-C9 NIL.Q-10-C9




NIL.Q

Code	Description	B	h	h1	Tube external diameter	Tube thickness
435210-*	NIL.Q-10-*	10	12	4	10	0,8+2,5
435212-*	NIL.Q-12-*	12	12	4	12	1+2
435213-*	NIL.Q-13-*	13	12	4	13	0,5+2
435215-*	NIL.Q-15-*	15	11.5	3	15	1+2
435216-*	NIL.Q-16-*	16	11.5	5	16	1+2,5
435218-*	NIL.Q-18-*	18	11.5	5	18	1,5+3
435220-*	NIL.Q-20-*	20	11.5	5	20	1+3
435222-*	NIL.Q-22-*	22	12	5	22	1+3,5
435225-*	NIL.Q-25-*	25	11.5	5	25	1+3
435228-*	NIL.Q-28-*	28	11.5	5	28	1+3
435230-*	NIL.Q-30-*	30	11.5	5	30	1+3
435232-*	NIL.Q-32-*	32	11.5	5	32	1+3,5
435234-*	NIL.Q-34-*	34	14.5	5	34	1+3
435235-*	NIL.Q-35-*	35	11.5	5	35	1+3
435238-*	NIL.Q-38-*	38	14.5	5	38	1+3,5
435240-*	NIL.Q-40-*	40	14.5	5	40	1+3
435245-*	NIL.Q-45-*	45	14.5	5	45	1+3

NIL.Q

Code	Description	B	h	h1	Tube external diameter	Tube thickness
435250-*	NIL.Q-50-*	50	14.5	5	50	1+2,5
435370-*	NIL.Q-50-2.6-*	50	24	5.5	50	2.6+4
435255-*	NIL.Q-55-*	55	14.5	5	55	2+4,5
435260-*	NIL.Q-60-*	60	15	5	60	1,5+3,5
435265-*	NIL.Q-65-*	65	21	5	65	1+3
435270-*	NIL.Q-70-*	70	22	5	70	2+5
435275-*	NIL.Q-75-*	75	21	6	75	2+4,5
435276-*	NIL.Q-76,2-*	76.2	21	6	76.2	2,5+5
435280-*	NIL.Q-80-*	80	21	6	80	1,5+4
435290-*	NIL.Q-90-*	90	21	6	90	3+5
435295-*	NIL.Q-95-*	95	21.5	6	95	3,5+5,5
435300-*	NIL.Q-100-*	100	21	7	100	1+4
435310-*	NIL.Q-110-*	110	24	6	110	3+5
435320-*	NIL.Q-120-*	120	30	5	120	2,5+6
435340-*	NIL.Q-140-*	140	34	3	140	4+7
435350-*	NIL.Q-150-*	150	28	7	150	5+8

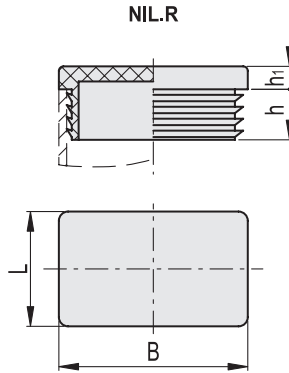

* Complete with colour index, example: 435410-C9 NIL.R-20x10-C9

C9 RAL9005 **C34** RAL7042

NIL.R


Code	Description	B	L	h	h1	Tube external diameter	Tube thickness
435410*	NIL.R-20x10*	20	10	12	3	20x10	0,8+2
435411*	NIL.R-20x15*	20	15	11.5	5	20x15	1+2
435430*	NIL.R-25x10*	25	10	11.5	3	25x10	0,8+2
435431*	NIL.R-25x15*	25	15	11.5	5	25x15	1+2,5
435432*	NIL.R-25x20*	25	20	11.5	5	25x20	1+3
435450*	NIL.R-30x10*	30	10	11.5	3	30x10	1+2
435451*	NIL.R-30x15*	30	15	11.5	5	30x15	1+2,5
435452*	NIL.R-30x20*	30	20	11.5	5	30x20	1+3
435470*	NIL.R-35x10*	35	10	11.5	3.5	35x10	1+2
435471*	NIL.R-35x20*	35	20	11.5	5	35x20	1+2,5
435472*	NIL.R-35x25*	35	25	11.5	5	35x25	1+3
435490*	NIL.R-40x15*	40	15	12	5	40x15	1+2
435491*	NIL.R-40x20*	40	20	12	5	40x20	1+3
435492*	NIL.R-40x25*	40	25	11.5	5	40x25	1+3
435493*	NIL.R-40x30*	40	30	11	5	40x30	1+3
435494*	NIL.R-40x35*	40	35	12	5	40x35	1+3
435510*	NIL.R-45x15*	45	15	11	5	45x15	1,5+2
435511*	NIL.R-45x20*	45	20	11.5	5	45x20	1+3
435512*	NIL.R-45x25*	45	25	12	5	45x25	1+3
435513*	NIL.R-45x30*	45	30	12	5	45x30	1+2,5
435514*	NIL.R-45x35*	45	35	12	5	45x35	1+3,5
435530*	NIL.R-50x20*	50	20	15	5	50x20	1+3
435531*	NIL.R-50x25*	50	25	11.5	5	50x25	1+3
435532*	NIL.R-50x30*	50	30	12	5	50x30	1+3
435533*	NIL.R-50x35*	50	35	14.5	5	50x35	1+3,5

NIL.R

Code	Description	B	L	h	h1	Tube external diameter	Tube thickness
435534*	NIL.R-50x40*	50	40	15	5	50x40	1,5+3
435550*	NIL.R-60x20*	60	20	14.5	5	60x20	1+3
435551*	NIL.R-60x25*	60	25	15	5	60x25	1+3
435552*	NIL.R-60x30*	60	30	15	5	60x30	1+2,5
435553*	NIL.R-60x35*	60	35	15	5	60x35	1,5+3,5
435554*	NIL.R-60x40*	60	40	14	5	60x40	1+3
435555*	NIL.R-60x45*	60	45	15	5	60x45	1,5+4
435556*	NIL.R-60x50*	60	50	14.5	5	60x50	1,5+3,5
435570*	NIL.R-70x20*	70	20	19	5	70x20	1+3,5
435571*	NIL.R-70x25*	70	25	18	5	70x25	1,5+2,5
435572*	NIL.R-70x30*	70	30	15	5	70x30	1+3
435573*	NIL.R-70x35*	70	35	15	5	70x35	1,5+3,5
435574*	NIL.R-70x40*	70	40	20	5	70x40	1,5+3
435590*	NIL.R-80x20*	80	20	18	5	80x20	1+3
435591*	NIL.R-80x30*	80	30	14.5	5	80x30	1+2,5
435592*	NIL.R-80x40*	80	40	14.5	5	80x40	1+3
435593*	NIL.R-80x50*	80	50	22	5	80x50	1,5+4
435594*	NIL.R-80x60*	80	60	25	5	80x60	1,5+3,5
435610*	NIL.R-90x20*	90	20	14.5	5	90x20	1+2,5
435611*	NIL.R-90x40*	90	40	15	5	90x40	2+4
435612*	NIL.R-90x50*	90	50	22	5	90x50	2+4,5
435630*	NIL.R-100x30*	100	30	15	5	100x30	1,5+3,5
435631*	NIL.R-100x40*	100	40	14.5	5	100x40	1,5+4
435632*	NIL.R-100x50*	100	50	24	5	100x50	1,5+4,5
435633*	NIL.R-100x60*	100	60	25	6	100x60	1,5+4,5




 Leveling feet and supports



Leveling feet and supports

4

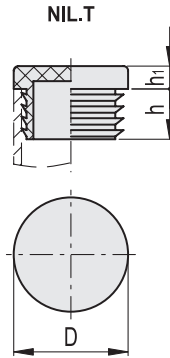

* Complete with colour index, example: 435010-C9 NIL.T-10-C9

C9
RAL9005

C34
RAL7042

NIL.T

Code	Description	D	h	h1	Tube external diameter	Tube thickness
435010.*	NIL.T-10.*	10	11	3.5	10	1+2
435012.*	NIL.T-12.*	12	11	3.5	12	1+2
435013.*	NIL.T-13.*	13	11	4	13	1+2
435014.*	NIL.T-14.*	14	11.5	5	14	1+2
435015.*	NIL.T-15.*	15	11.5	3	15	1+2
435016.*	NIL.T-16.*	16	11	5	16	1+2
435018.*	NIL.T-18.*	18	11.5	5	18	1+2
435019.*	NIL.T-19.*	19	11.5	5	19	1+2,5
435020.*	NIL.T-20.*	20	11.5	5	20	1+2,5
435022.*	NIL.T-22.*	22	11.5	5	22	1+2
435023.*	NIL.T-23.*	23	11.5	5	23	1+2,5
435024.*	NIL.T-24.*	24	11.5	5	24	1+2,5
435025.*	NIL.T-25.*	25	11.5	5	25	1+3
435026.*	NIL.T-26.*	26	11.5	5	26	1+3
435027.*	NIL.T-27.*	27	11.5	5	27	1+3
435028.*	NIL.T-28.*	28	11.5	5	28	1+3
435030.*	NIL.T-30.*	30	11.5	5	30	1+2,5
435032.*	NIL.T-32.*	32	12	5	32	1+3
435034.*	NIL.T-34.*	34	11.5	5	34	1+3
435035.*	NIL.T-35.*	35	11.5	5	35	1+3
435036.*	NIL.T-36.*	36	11.5	5	36	1+3
435037.*	NIL.T-37.*	37	11.5	5	37	1+3
435038.*	NIL.T-38.*	38	11.5	5	38	1+3,5

NIL.T

Code	Description	D	h	h1	Tube external diameter	Tube thickness
435040.*	NIL.T-40.*	40	11.5	5	40	1+3
435042.*	NIL.T-42.*	42	11.5	5	42	1+3
435045.*	NIL.T-45.*	45	11	5	45	1+3
435046.*	NIL.T-46.*	46	11.5	5	46	1,5+3,5
435048.*	NIL.T-48.*	48	11.5	5	48	1,2+3,6
435050.*	NIL.T-50.*	50	14.5	5	50	1+2,5
435150.*	NIL.T-50-2.5.*	50	11.5	5	50	2,5+4,5
435052.*	NIL.T-52.*	52	14.5	5	52	1,5+3,5
435055.*	NIL.T-55.*	55	11.5	5	55	1+3
435155.*	NIL.T-55-3.*	55	14.5	5	55	3+5
435060.*	NIL.T-60.*	60	14.5	5	60	1,5+3
435160.*	NIL.T-60-3.*	60	17.5	5	60	3+5
435065.*	NIL.T-65.*	65	14.5	5	65	1,5+3,5
435070.*	NIL.T-70.*	70	21	5	70	1,5+3,5
435075.*	NIL.T-75.*	75	21.5	6	75	1+3,5
435076.*	NIL.T-76.*	76	21.5	6	76	1,6+4
435080.*	NIL.T-80.*	80	22	5	80	1,5+3
435085.*	NIL.T-85.*	85	21	6	85	1,5+4
435088.*	NIL.T-88.*	88	21.5	6	88	1,5+4
435090.*	NIL.T-90.*	90	21	6	90	1,5+5
435095.*	NIL.T-95.*	95	21	6	95	1,5+4
435110.*	NIL.T-100.*	100	28.5	6	100	2+4,5