


OA4715 'Challenger Series'



AC Fans - 115, 230V
120mm x 38.5mm (4.72" x 1.52")

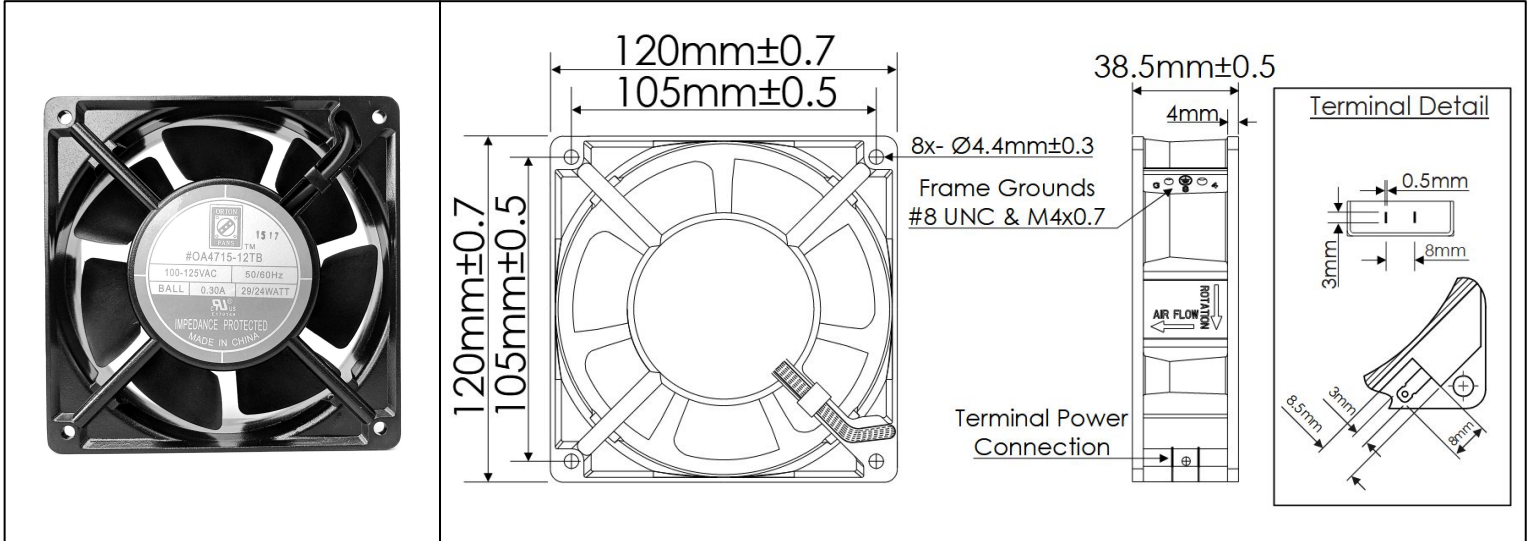

Frame	Die Cast Aluminum, Black	Operating Temperature -40°C ~ +70°C Storage Temperature -40°C ~ +80°C Life Expectancy 50,000 Hours (L10 at 25°C) Weight: 1.11 lbs.
Impeller	PBT, UL94 V-0 Plastic	
Connection	2x Terminals	
Motor	AC Shaded Pole, Impedance Protected	
Bearing System	Dual Ball Bearings	
Dielectric Strength	1500VAC/min, <1mA	
Insulation Resistance	≥10MΩ @ 500 VDC	

Part Number	Rated Voltage (Volts AC)	Frequency (Hertz)	Rated Input (Watts)	Rated Current (Amps)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H ₂ O)
OA4715-12TB	115	50 / 60	29 / 24	0.30	2575 / 2980	96.7 / 110	40.4 / 44.2	0.29 / 0.37
OA4715-23TB	230	50 / 60	28 / 24	0.20	2575 / 2980	96.7 / 110	40.4 / 44.2	0.29 / 0.37