

Part number

CX 6.0 PM



Male pneumatic contact, without closing valve, for tubes with internal diameter 6 mm

Product description

Product type	Pneumatic contact
Gender	Male
Specification	Without closing valve For tubes with internal diameter 6 mm

Further technical details

Weight	1,32 g
Operating temperature range (min, max)	-40°C ... +125°C

Material properties

Main material	Polyamide (PA)
RoHs conformity	Compliant
China RoHs - EFUP	E
REACH SVHC substances	No

General ordering information

EAN13 code	8015747096102
eCl@ss 8.1	27440204
ETIM 7.0	EC000796

Packaging Information


Sub-packaging length	50,00 mm
Sub-packaging height	44,00 mm
Sub-packaging width	50,00 mm
Sub-packaging volume	0,11 dm ³
Sub-packaging description	Plastic box
Sub-packaging quantity	10 Pcs
Sub-packaging EAN barcode	8015747102575

Part number

CX 6.0 PM



Catalogue drawings

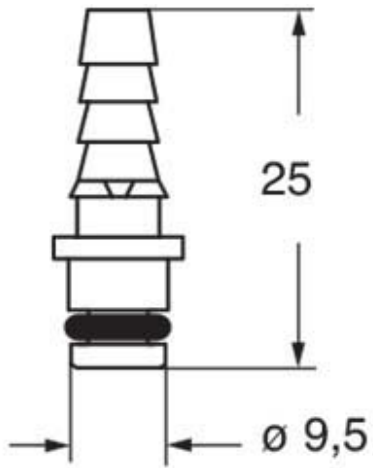

Notes

Dimensions shown in mm are not binding and may be changed without notice.
